


DURACELL™

ALKALINE MANGANESE

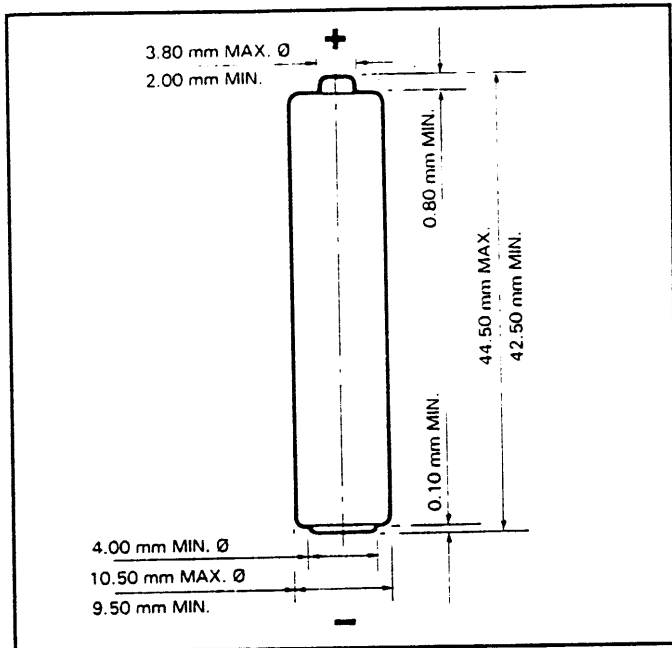

Specification:

Nominal Voltage:	1.5 V
Nominal Capacity:	1.050 mAh
Life:	7.2 h on 10 Ω to 0.8 V at 20°C
Nominal Impedance:	0.23 Ω at 1 kHz
Recomm. Load Range at 20°C:	1 Ω — 22 kΩ
Volume:	3.6 cm ³
Average Weight:	11 g
I.E.C. Designation:	LR03

Typical discharge characteristics

