


- 908-526

- MN 1604

DURACELL®

ALKALINE MANGANESE


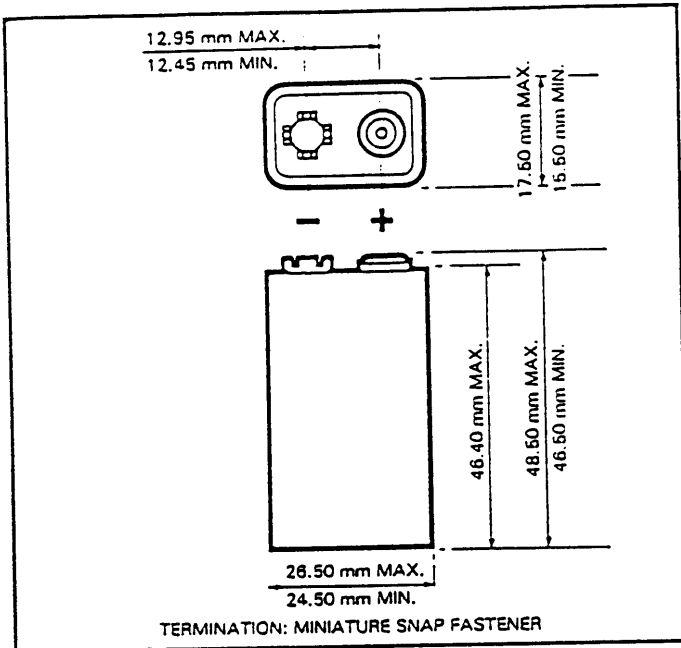


Specification:

Nominal Voltage:	9.0 V
Nominal Capacity:	550 mAh
Life:	36 h on 470 Ω to 4.8 V at 20°C
Nominal Impedance:	1.6 Ω at 1 kHz
Recomm. Load Range at 20°C	47 Ω — 470 k Ω
Volume:	21 cm ³
Average Weight:	45 g
I.E.C. Designation:	6LR61

Mercury content less than 0.025% of total weight.

Typical discharge characteristics

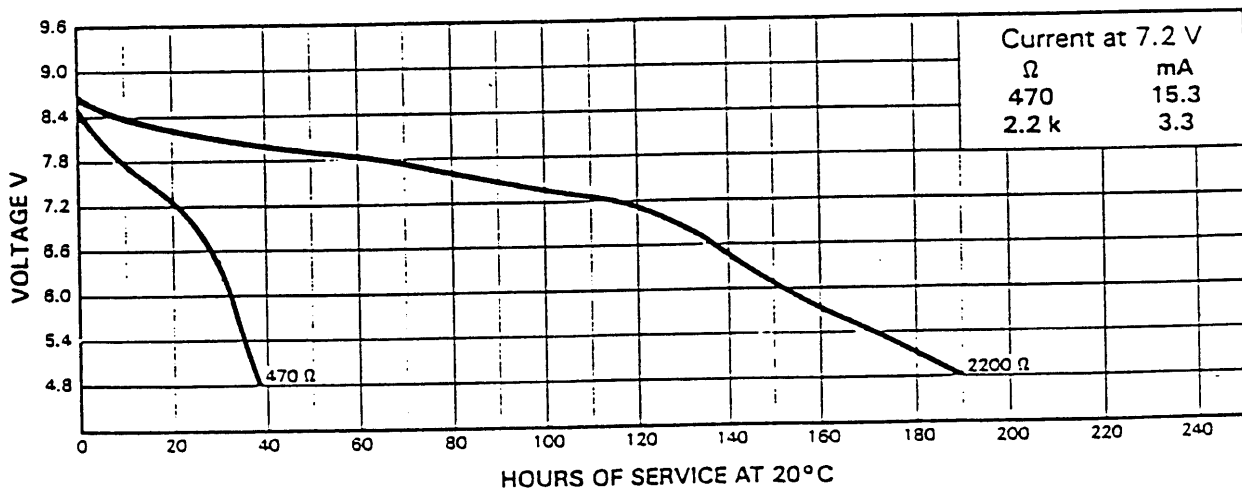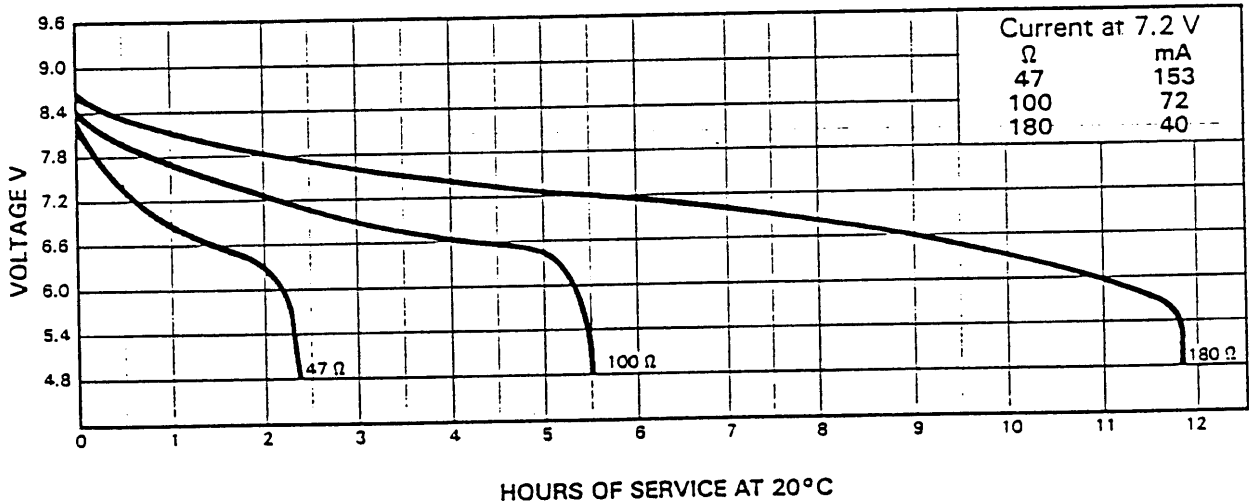

ISSUE: 6A

The Duracell Group of Companies reserves the right to change this specification without prior notice.