




7069108 → 7069145

2029

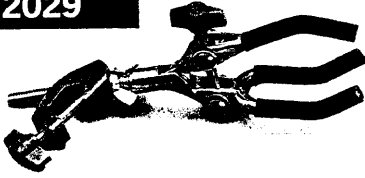

1029

**3 - PRONG UTILITY CLAMP**

As number 1020 but fitted with a screwed shaft and nickel plated bosshead which can be screwed up and down shaft 35 mm and locked in any position with a wing nut. The bosshead accepts rods up to 13 mm which are secured with a stainless steel thumb screw.


2029

7069145

**3 - PRONG UTILITY CLAMP**

As number 1029 but the jaws are rubber covered and the bosshead is painted blue acrylic with a blue plastic headed nickel plated steel screw.

1030

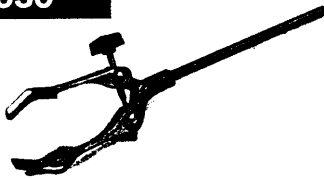


1030

**REXALOY UNIVERSAL CLAMP**

Diecast in aluminium alloy and fitted with a stainless steel shaft. The clamp accepts articles up to 100 mm diameter. Actuated by nickel plated brass pummels and blue plastic headed nickel plated steel twin screw. The jaws are cork lined.

1030/3

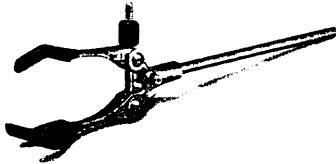

1030/1

**REXALOY UNIVERSAL CLAMP**


As number 1030 but jaws coated in a blue chemical resistant plastic.

1030/3

**REXALOY UNIVERSAL CLAMP**

As number 1030/1 but jaws spring loaded.

Z0104

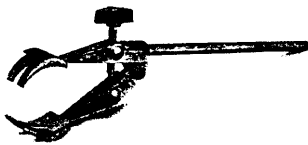

1030/4

**REXALOY UNIVERSAL CLAMP**

As number 1030 but with an aluminium shaft.


Z0104

7069108

**RETORT CLAMP**

Diecast in alloy and fitted with an aluminium shaft. The clamp accepts articles up to 85 mm diameter. Actuated by nickel plated brass pummels and blue plastic headed nickel plated steel twin screw. The four interlocking jaws are cork lined.

9100

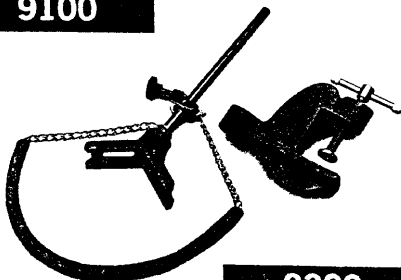

9100

**CHAIN CLAMP**

Rubber covered chain with cork lined jaws will support articles from 0 to 150 mm diameter. Jaws are tightened by use of a plastic headed screw. The shaft and tensioner parts are nickel plated. The shaft diameter is 10 mm.

2309

2309

**BENCH END CLAMP (G CLAMP)**

For clamping to edge of bench. For use with 13 mm rods or tubes which are secured by socket headed screws. The clamp is made of cast iron and painted blue acrylic. One allen key provided with each clamp.