



## Shape 1:1


KPE-202

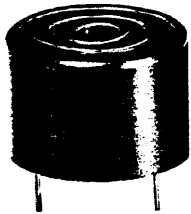

KPE-202A

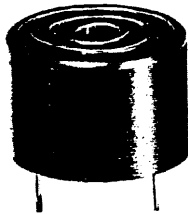


KPE-212

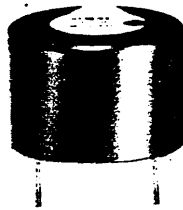

(Sealed Type)

KPE-212A

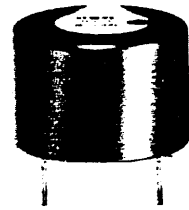


(Sealed Type)


Model Number	KPE-202	KPE-202A	KPE-212	KPE-212A
Oscillating Frequency (KHz)	2.9 ± 0.5	2.9 ± 0.5	2.9 ± 0.5	2.9 ± 0.5
Operating Voltage (VDC)	3~20	3~20	3~20	3~20
Current Consumption at 12VDC (mA, maximum)	6	8	6	8
Sound Pressure Level at 30cm/12VDC (dB, minimum)	78	83	78	83
Tone	Continuous	Continuous	Continuous	Continuous
Operating Temperature ( °C )	-20~+60	-20~+60	-20~+60	-20~+60
Storage Temperature ( °C )	-30~+70	-30~+70	-30~+70	-30~+70
Weight (Gram)	7	4.5	7	7
Packing Quantity (PCS/BOX)	250	250	250	250

## Dimension


KPE-202

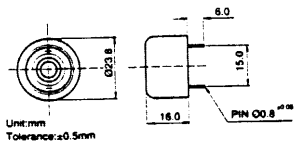


KPE-202A

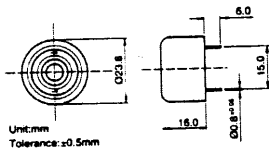

KPE-212

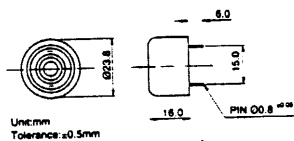

KPE-212A

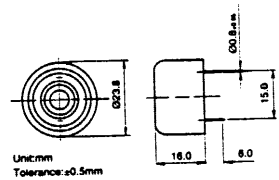

## Characteristic

