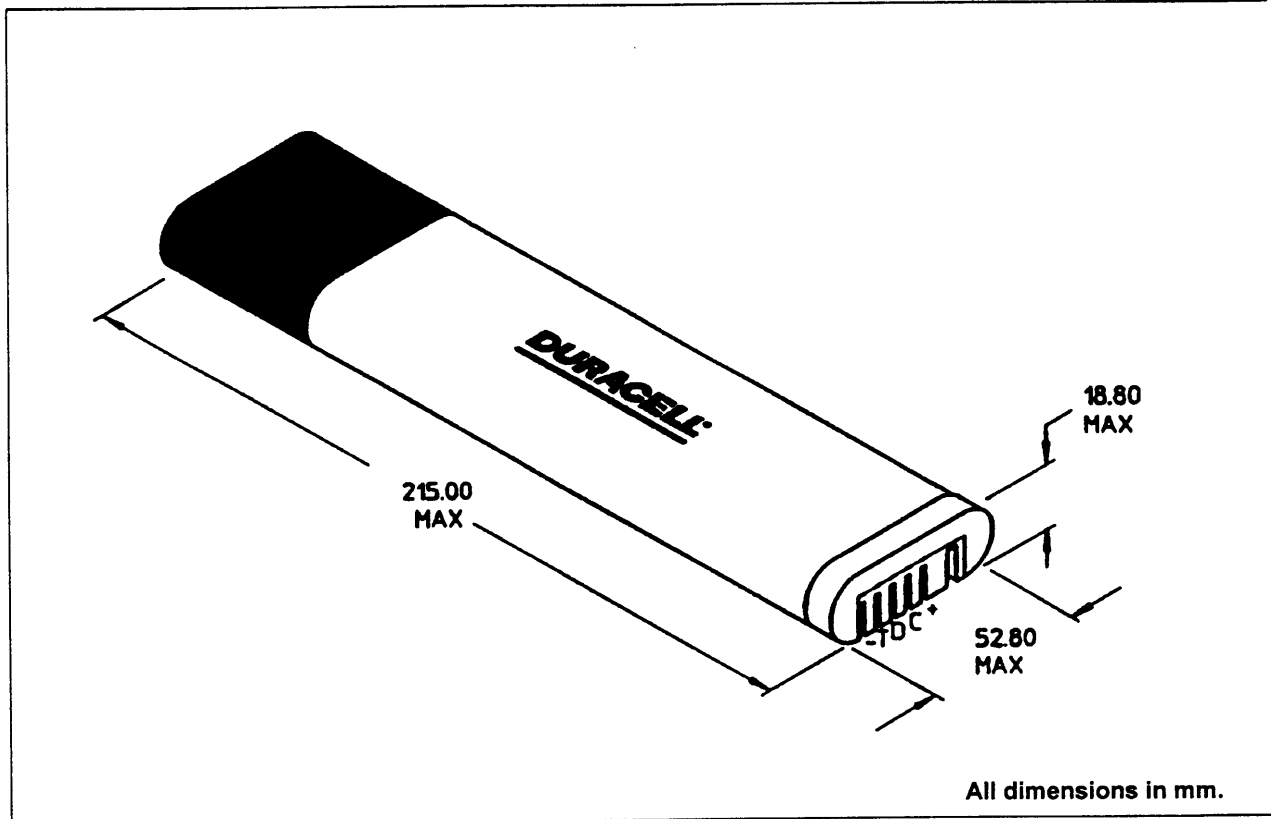


724-099

DURACELL®**SIZE DR35****Nickel Metal Hydride Battery****SPECIFICATIONS**

| | |
|------------------------------|--------------------------|
| Nominal Voltage: | 10.8 V |
| Min. On Load Voltage: | 10.8V on 4.8 amps at 10s |
| Rated Capacity: | 2400 mAh at C/5 to 9.0V |
| Average Weight: | 470g |

**CHARGING**

Optimum dischargeable capacity may be achieved using a three stage charge regime:

| Rate | Current(mA) | Purpose | Termination | Temperature Range |
|--------------|-------------|---------------|--------------------------------|-------------------|
| C | 2400 | Main Charge | $-\Delta V, \Delta T/\Delta t$ | +10° C to +45° C |
| Followed by | | | | |
| C/10 | 240 | Top-up Charge | Timed 30 Min | 0° C to + 45° C |
| Followed by | | | | |
| C/300 | 8 | Charge Maint | None Required | +10° C to +35° C |

DURACELL® Batteries.**Issue 5E**

To be read in conjunction with the General Information module
 In line with its continuing development programme, Duracell reserves the right to alter specifications without prior notice