


# TR114N

## DURACELL®


### MERCURIC OXIDE

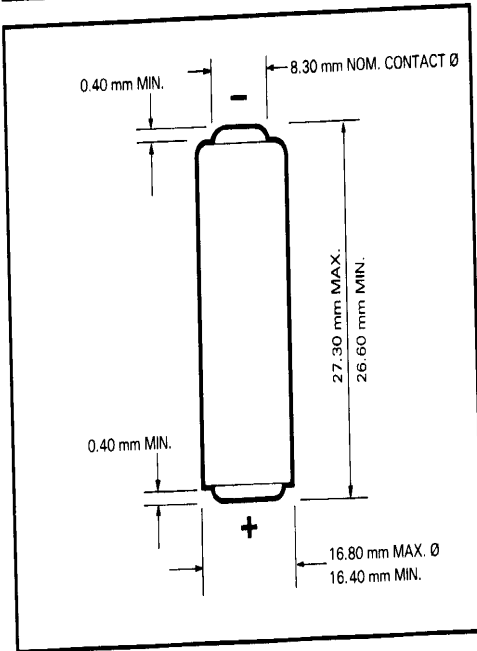

#### Specification:

Nominal Voltage:	5.4 V
Nominal Capacity:	400 mAh
Life:	75 h on 1 k $\Omega$ to 3.6 V at 20°C
Volume:	6 cm <sup>3</sup>
Average Weight:	20 g

#### Typical discharge characteristics

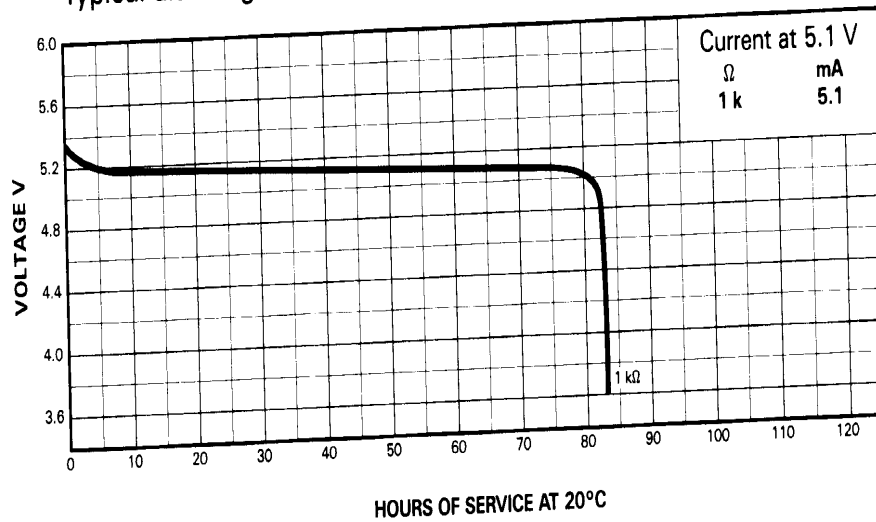

ISSUE: 4P

The Duracell Group of Companies reserves the right to change this specification without prior notice.