


3849510  
3849521

# Motorola T6222 Yellow

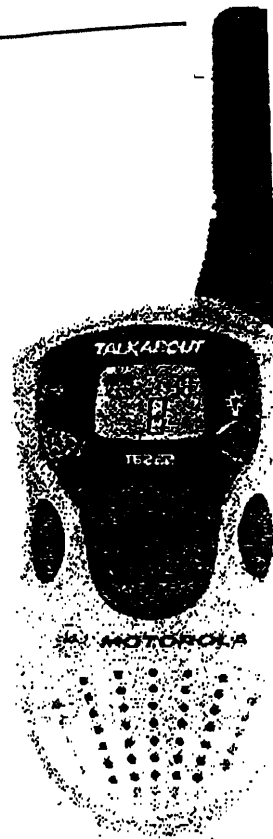

Motorola T6222 Yellow

Backlight LED

Time Out Timer

5 Audible Call Alerts

Lock Button - disables scroll, menu & scan button

Battery Meter (always shown in display)

Signal Strength Indicator

Channel Scanning

Vibracall

Speech Scrambling



T6222 Yellow complete with 8 channels, 38 tone groups, VOX, belt clip and user guide.

3 x AA batteries are required but not included.

8 channels and 38 codes - allows 304 talk combinations

Auto Power Off

Talk Confirmation Tone option

VOX Hands-Free

Quiet6000™ Talk

Ring Alert

36 Segment LCD display with icons

### Specifications:

Description	Specs	
Channels	8	
Codes	38	
Operating Frequency	446.00625-446.09375 MHz	
Talk Range	Up to 3 kilometres	
Power Source	3 AA Batteries or NiMH Battery pack.	
<b>Battery Life*:</b>	<b>AA**</b>	<b>NiMH</b>
Continuous Talk Time	8.2 Hours	2.4 Hour
Standby Time	130 Hours	39 Hours

\* Typical

\*\* With premium quality alkaline cells. Battery life with third party