


Basic series
2 mm embeddable

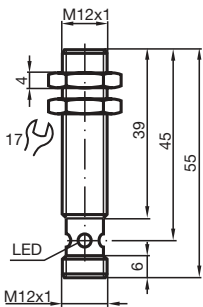

Switching element function	DC	Make function
Installation	embeddable	
Rated operating distance s_n	2 mm	
Assured operating distance s_a	0 ... 1.62 mm	
Reduction factor r_{V2A}	0.67	
Reduction factor r_{Al}	0.18	
Reduction factor r_{Cu}	0.12	
Operating voltage U_B	5 ... 60 V	
Operating current I_L	2 ... 100 mA	
Switching frequency f	0 ... 1000 Hz	
Off-state current I_r	≤ 0.5 mA	
Voltage drop U_d	≤ 5 V	
Short circuit protection	pulsing	
Polarity reversal protected	tolerant	
Indication of the switching state	ring LED, yellow	
Ambient temperature	$-25 \dots 70$ °C (248 ... 343 K)	
Protection degree	IP67	
Connection type	V1-connector	
Housing material	brass, nickel plated	
Sensing face	PBT	
Standard conformity	EN 60947-5-2	

Connection

