

658-522 .530  
658-558

**ST 18/3poles  
Female parts**

black/white


green




coding

/11


with double screw connector  
strain relief for one round cable  
diameter 6.5–8.3 mm

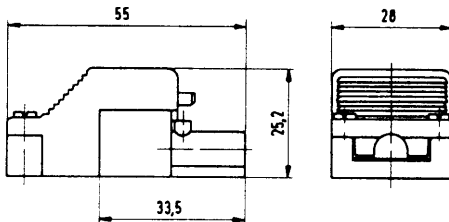

single screw connector  
strain relief for one round cable  
diameter 6.5–8.3 mm

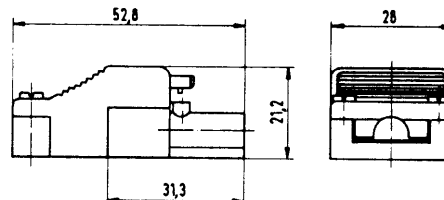

double screw connector  
strain relief for two round cables  
diameter 4.5–10.0 mm  
or one flat cable

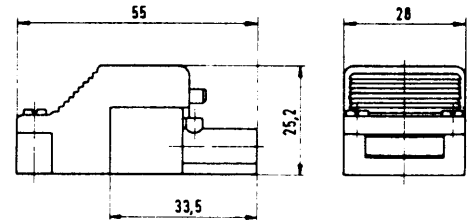

colour


POP

colour


POP

colour


POP

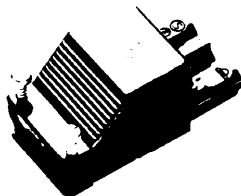

**female part assembled**  
with strain relief without locking device  
black **93.731.3353.0** 100  
white **93.731.3350.0** 100

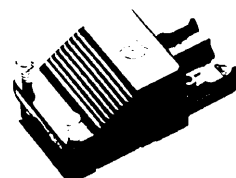

**female part assembled**  
with strain relief without locking device  
black **93.731.3253.0** 100  
white **93.731.3250.0** 100  
green/black<sup>1</sup> **93.731.3750.0** 100

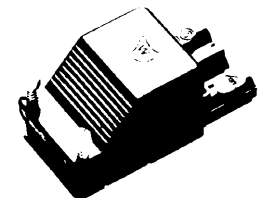

**female part assembled**  
with strain relief without locking device  
black **93.631.3353.0** 100  
white **93.631.3350.0** 100

**female part assembled**  
with strain relief with locking device  
black **93.731.4353.0** 100  
white **93.731.4350.0** 100

**female part assembled**  
with strain relief with locking device  
black **93.731.4253.0** 100  
white **93.731.4250.0** 100  
green/black<sup>1</sup> **93.731.4750.0** 100

**female part assembled**  
with strain relief with locking device  
black **93.631.4353.0** 100  
white **93.631.4350.0** 100

**female part unassembled**  
with strain relief without locking device  
black **93.931.3353.0** 200  
white **93.931.3350.0** 200


**female part unassembled**  
with strain relief without locking device  
black **93.931.3253.0** 200  
white **93.931.3250.0** 200  
green/black<sup>1</sup> **93.931.3750.0** 200

**female part unassembled**  
with strain relief without locking device  
black **93.831.3353.0** 200  
white **93.831.3350.0** 200


**female part unassembled**  
with strain relief with locking device  
black **93.931.4353.0** 200  
white **93.931.4350.0** 200

**female part unassembled**  
with strain relief with locking device  
black **93.931.4253.0** 200  
white **93.931.4250.0** 200  
green/black<sup>1</sup> **93.931.4750.0** 200


**female part unassembled**  
with strain relief with locking device  
black **93.831.4353.0** 200  
white **93.831.4350.0** 200

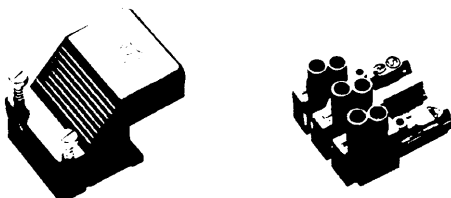

**female part**  
black **93.031.3353.0** 200  
white **93.031.3350.0** 200

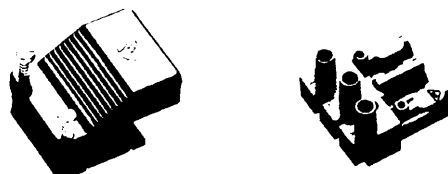

**female part**  
black **93.031.3253.0** 200  
white **93.031.3250.0** 200  
green **93.031.3750.0** 200

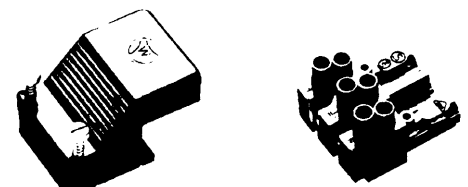

**female part**  
black **93.031.3353.0** 200  
white **93.031.3350.0** 200

**strain relief complete with top and bottom part**  
without locking device  
black **27.410.8253.0** 200  
white **27.410.8250.0** 200

**strain relief complete with top and bottom part**  
without locking device  
black **27.410.8153.0** 200  
white **27.410.8150.0** 200

**strain relief complete with top and bottom part**  
without locking device  
black **27.410.5253.0** 200  
white **27.410.5250.0** 200

**strain relief complete with top and bottom part**  
with locking device  
black **27.410.8453.0** 200  
white **27.410.8450.0** 200

**strain relief complete with top and bottom part**  
with locking device  
black **27.410.853.0** 200  
white **27.410.8550.0** 200

**strain relief complete with top and bottom part**  
with locking device  
black **27.410.5453.0** 200  
white **27.410.5450.0** 200

female part green, strain relief black  
(attention: watch coding!)