



UNC #4-40 Hexscrew

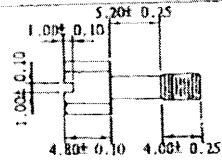



VIDEK LTD.

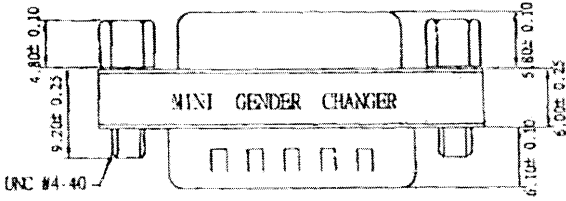

DGC 15 M/F GENDER CHANGER

PIN OUT: 15Male

15Female

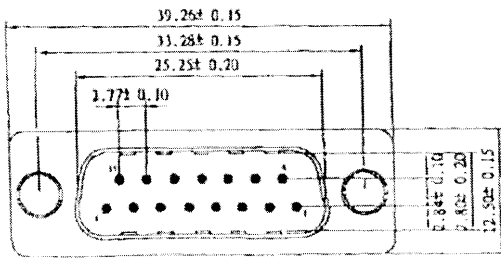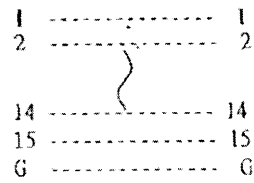

Label: yellow color with black character

One side: MINI GENDER CHANGER

The other side: U.S.A. PATENT 5199906 ISSUED

SPECIFICATION

INSULATOR: PBT Glass fibre reinforced UL 94 VO

CONTACT: Brass

CONTACT PLATING: Gold plated over nickel

SHELL: Tin plated shell

CURRENT RATING: 3 AMP

DIELECTRIC STRENGTH: 1000V AC for one minute

INSULATOR RESISTANCE: 1000MΩ min at 500V DC

TEMPERATURE: -55°C — +105°C

UNIT: m/m

REV.	DESCRIPTION	REVISED DETAILS	DATE	REVISED BY	Part number:	Revision:
					B044	ORIG.
					HPQ number:	Drawing #: B044
						Scale: None
						Date:
						SALES :

3252152 + 467637
 ↓ 2164
 ↓ 2176