




A friend for life

263-606

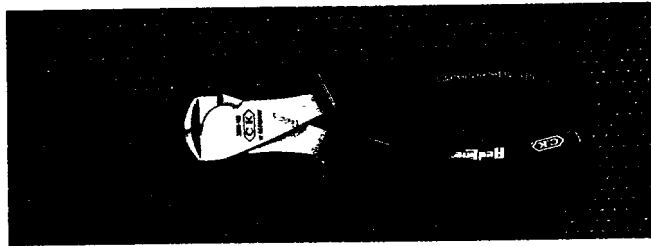


Redline HEAVY DUTY TOP CUTTERS 3806 ▲

Manufactured from hot drop forged special tool steel, oil hardened and tempered to specified levels. Induction hardened cutting edges to 60-61 HRC. Heavy duty design gives high leverage which cuts even piano wire with ease. Manufactured to ISO 5748 and DIN 5252A Specifications. Display packed on clip hanger.

Size	160mm / 6"
Order Ref	T3806
Weight:	255g
Box Qty:	3
Cutting Capacity: mm Ø	
Piano Wire:	1.5
Hard Wire:	2.0
Med/ Hard Wire:	2.8
Soft Wire:	> 4.0

ISO 5748, DIN 5252A

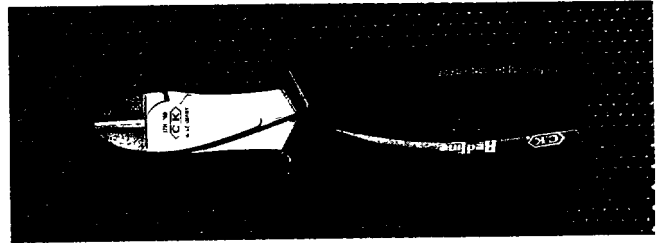


Redline HEAVY DUTY SIDE CUTTERS 3720 ▲

Hot drop forged special tool steel, oil hardened and tempered, cutting edges induction hardened to 60-61 HRC with all Redline features. Heavy duty design gives extra leverage for strength and smooth cutting. Manufactured to ISO 5749 and DIN 5238A Specifications. Display packed on clip hanger.

Size	145mm / 5 7/8"	165mm / 6 1/2"	200mm / 8"
Order Ref	T3720 55	T3720 65	T3720 8
Weight:	190g	260g	315g
Box Qty:	3	3	3
Cutting Capacity mm Ø			
Piano Wire:	1.5	2.0	2.5
Hard Wire:	2.0	2.5	3.0
Med/ Hard Wire:	2.8	3.0	4.2
Soft Wire:	> 4.0	> 4.0	> 4.0


ISO 5749, DIN 5238A

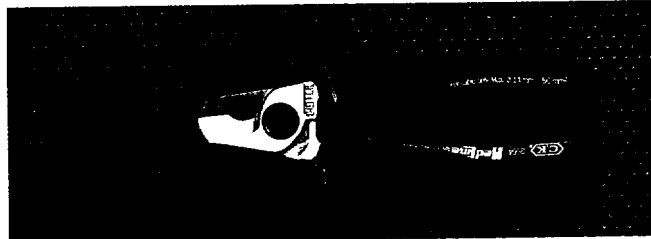

Redline CABLE CUTTERS 3964 ▲

For one handed use on cables up to 14mm / 1/2" in diameter (50mm²). Compact but extremely powerful on copper and aluminium cable. Razor sharp edges cut cleanly through cable with no 'squeeze', additional knife like edges can also split insulation with ease. Not suitable for steel wire. Display packed on clip hanger.

Size:	165mm / 6 1/2"
Order Ref:	T3964 6
Weight:	270g
Box Qty:	3

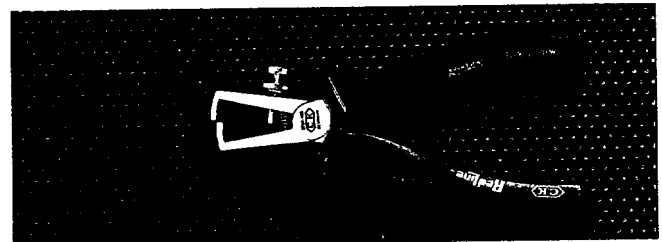


Redline WIRE STRIPPING PLIERS 3754 ▲

Ideal product for repetitive work with soft PVC handles and coil spring. Adjustable capacity using the brass setting screw and lock nut. Wire capacity of 0.3-5.0mm diameter. Manufactured with all Redline features and to DIN 5232 Specifications. Display packed on clip hanger.

Size:	160mm / 6"
Order Ref:	T3754
Weight:	188g
Box Qty:	3

DIN 5232.

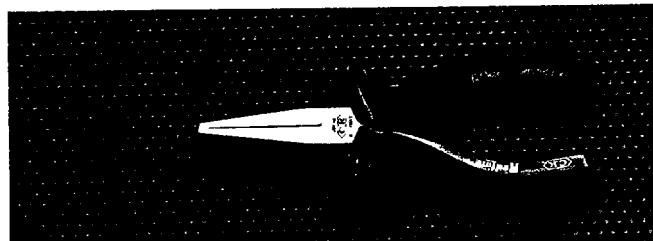


Redline FLAT NOSE PLIERS 3807 ▲

Manufactured from hot drop forged special tool steel. Oil hardened and tempered to specified levels with all Redline features. Cut inside jaws for extra grip and ease of handling. Manufactured to ISO 5745 and DIN 5248 Specifications. Display packed on clip hanger.

Size	160mm / 6"
Order Ref	T3807
Weight	187g
Box Qty	3

ISO 5745, DIN 5248

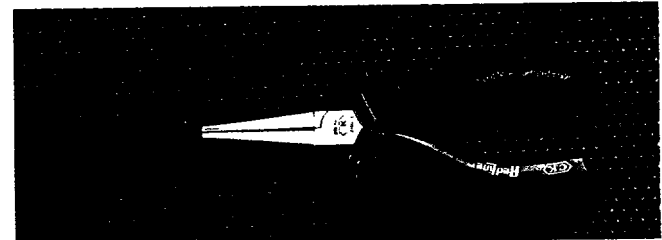

Redline ROUND NOSED PLIERS 3808 ▲

Cut inside jaws for ease of handling. Manufactured to ISO 5745 and DIN 5249 Specifications. Comfort PVC handles, matt chrome finish and all other Redline features. Display packed on clip hanger.

Size:	160mm / 6"
Order Ref	T3808
Weight:	179g
Box Qty	3

ISO 5745, DIN 5249

Redline PLIERS