


J O B B E R D R I L L S

Straight Shank
Standard Helix

BS 328 DIN 338 ISO 235/1

	Range	Finish
01 000 HSS	1/16"-3/4"	P1 Blue
01 000	1.55mm-25.00mm	P1 Blue
01 030 HSS	1/64"-3/4"	Bright
	0.30mm-25.00mm	Bright
01 005 HSS	3/64"-3/4"	TiN
	1.00mm-20.00mm	TiN

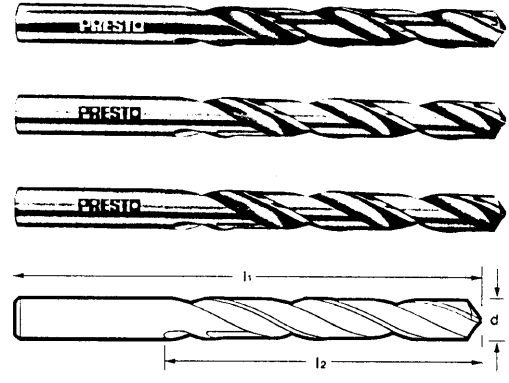

Point Angle 118° General Purpose

Dia	Flute Length	Overall Length	01000	01005
in	mm	mm	01030	Availability
d	l ₂	l ₁		

Dia	Flute Length	Overall Length	01000	01005
in	mm	mm	01030	Availability
d	l ₂	l ₁		

Dia	Flute Length	Overall Length	01000	01005
in	mm	mm	01030	Availability
d	l ₂	l ₁		

	*0.30	4	19	•	-		1.80	22	46	•	•		3.95	43	75	•	•
	*0.32	4	19	•	-		1.85	22	46	•	•	5/32	4.00	43	75	•	•
	*0.35	4	19	•	-		1.90	22	46	•	•		4.05	43	75	•	•
	*0.38	4	19	•	-		1.95	24	49	•	•		4.10	43	75	•	•
*1/64	*0.40	5	20	•	-	5/64	2.00	24	49	•	•		4.15	43	75	•	•
	*0.42	5	20	•	-		2.05	24	49	•	•		4.20	43	75	•	•
	*0.45	5	20	•	-		2.10	24	49	•	•		4.25	43	75	•	•
	*0.48	5	20	•	-		2.15	27	53	•	•		4.30	47	80	•	•
	*0.50	6	22	•	-		2.20	27	53	•	•		4.35	47	80	•	•
	*0.52	6	22	•	-		2.25	27	53	•	•	11/64	4.40	47	80	•	•
	*0.55	7	24	•	-		2.30	27	53	•	•		4.45	47	80	•	•
	*0.58	7	24	•	-		2.35	27	53	•	•		4.50	47	80	•	•
	*0.60	7	24	•	-	3/32	2.40	30	57	•	•		4.55	47	80	•	•
	*0.62	8	26	•	-		2.45	30	57	•	•		4.60	47	80	•	•
	*0.65	8	26	•	-		2.50	30	57	•	•		4.65	47	80	•	•
	*0.68	9	28	•	-		2.55	30	57	•	•		4.70	47	80	•	•
	*0.70	9	28	•	-		2.60	30	57	•	•		4.75	47	80	•	•
	*0.72	9	28	•	-		2.65	30	57	•	•	3/16	4.80	52	86	•	•
	*0.75	9	28	•	-		2.70	33	61	•	•		4.85	52	86	•	•
*1/32	*0.78	10	30	•	-		2.75	33	61	•	•		4.90	52	86	•	•
	*0.80	10	30	•	-	7/64	2.80	33	61	•	•	-	4.95	52	86	•	•
	*0.82	10	30	•	-		2.85	33	61	•	•		5.00	52	86	•	•
	*0.85	10	30	•	-		2.90	33	61	•	•		5.10	52	86	•	•
	*0.88	11	32	•	-		2.95	33	61	•	•		5.15	52	86	•	•
	*0.90	11	32	•	-		3.00	33	61	•	•	13/64	5.20	52	86	•	•
	*0.92	11	32	•	-		3.05	36	65	•	•		5.25	52	86	•	•
	*0.95	11	32	•	-		3.10	36	65	•	•		5.30	52	86	•	•
	*0.98	12	34	•	-		3.15	36	65	•	•		5.35	57	93	•	•
	*1.00	12	34	•	•		3.20	36	65	•	•		5.40	57	93	•	•
	*1.05	12	34	•	•	1/8	3.25	36	65	•	•		5.45	57	93	•	•
	*1.10	14	36	•	•		3.30	36	65	•	•		5.50	57	93	•	•
*3/64	*1.15	14	36	•	•		3.35	36	65	•	•	7/32	5.55	57	93	•	•
	*1.20	16	38	•	•		3.40	39	70	•	•		5.60	57	93	•	•
	*1.25	16	38	•	•		3.45	39	70	•	•		5.65	57	93	•	•
	*1.30	16	38	•	•		3.50	39	70	•	•		5.70	57	93	•	•
	*1.35	18	40	•	•		3.55	39	70	•	•		5.75	57	93	•	•
	*1.40	18	40	•	•		3.60	39	70	•	•	9/64	5.80	57	93	•	•
	*1.45	18	40	•	•		3.65	39	70	•	•		5.85	57	93	•	•
	*1.50	18	40	•	•		3.70	39	70	•	•		5.90	57	93	•	•
1/16	1.55	20	43	•	•		3.75	39	70	•	•	15/64	6.00	57	93	•	•
	1.60	20	43	•	•		3.80	43	75	•	•		6.05	63	101	•	•
	1.65	20	43	•	•		3.85	43	75	•	•		6.10	63	101	•	•
	1.70	20	43	•	•		3.90	43	75	•	•		6.15	63	101	•	•
	1.75	22	46	•	•												

* Available Bright Finish Only