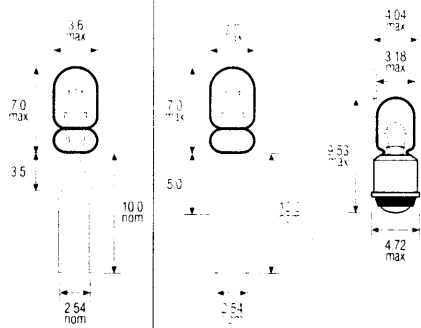


LAMP DATA

328-662
" 650
" 649

T-1 Sub-Miniature									
Volts	Amps	Lumens	MSCP	Life (hours)	Filament shape				
						T-1 3mm Glass Bi-Pin 'A'	T-1 3mm Glass Bi-Pin 'B'	T-1 3mm Submidjet Flange SX4s	
5	0.02	0.4	0.034	10,000	C-2R			8022	
5	0.06	0.4	0.03	60,000	C-2R			682	
5	0.06	0.6	0.05	40,000	C-2R	7683GA	7683GB	685	
5	0.06	1.9	0.15	5,000	C-2R			6180	
5	0.075	1.1	0.09	40,000	C-2R			714	
5	0.115	1.9	0.15	40,000	C-2R	7715GA	7715GB	718	
8	0.05	1.2	0.095	10,000	C-2F	8595GA	8595GB		
12	0.06	1.9	0.15	16,000	C-2F	8097GA	8097GB	32	
14	0.04	1.5	0.12	16,000	C-2F	3092GA	3092GB		
14	0.065	1.9	0.15	16,000	C-2F	8098GA	8098GB		
18	0.026	1.9	0.15	10,000	C-2F			7241	
28	0.024	1.6	0.13	4,000	CC-2F			6839	
NOTES All dimensions in mm. Drawings not to scale This sheet lists a selection of available lamps Please enquire for other ratings and sizes Special options: Aged and selected Colour coated bulbs Silicone rubber filters						Lead wire diameter 0.35	Lead wire diameter 0.35	Cap previously designated SX3s	