




This is a sample photo.

Order symbol	MCE PC 9 MF/M		
EI. number	EAN-code	6418074007599	
Sweden			
Denmark			
Finland	3422203		
Including	Multi-FEM membrane cable glands, two PEN 10 mm ² bars in plastic support, DIN 35 rails mounted in place, wall mount cover plugs FEP 26150.		
Product Properties	USA: NEMA 1, 4, 4X, 6, 12, 13		
	EURO: IP 65 (EN 60529); IK 08 (EN 50102)		

MCE CONTROL

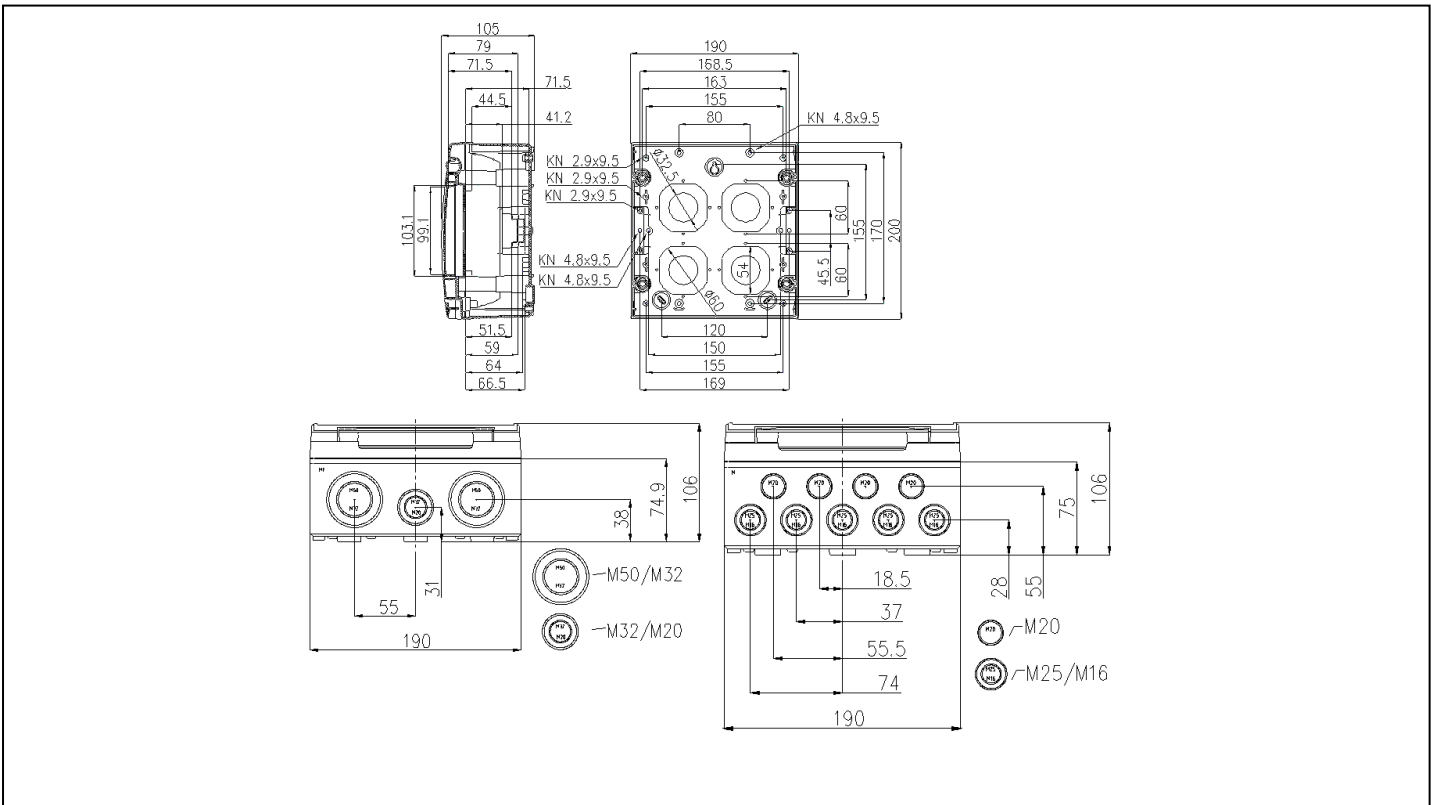

Technical Information of Product Group

Standard colour: RAL 7035

Flame resistance: UL-94 5 V

Temp. range-in cont. use: - 40° ... 80° C

Temp. range-of material: - 40° ... 120° C

Accessories

- Membrane cable gland FEM 5-7
- Membrane cable gland FEM 7-10
- Membrane cable gland MFM 8-12
- Membrane cable gland FEM 10-14/25
- Membrane cable gland FEM 14-20
- Membrane cable gland FEM 26-35
- Cover plug FEP 26150
- Lock MR 26065
- Sealing bushing DP 14553
- Multiadapter for PEN-bars MU 26138