




This is a sample photo.

<b>Order symbol</b>	MCE PC 14 MF/M		
<b>EI. number</b>	<b>EAN-code</b>	6418074007605	
Sweden			
Denmark			
Finland	3422206		

**Including**  
Multi-FEM membrane cable glands, two PEN 10 mm<sup>2</sup> bars in plastic support, DIN 35 rails mounted in place, wall mount cover plugs FEP 26150.

**Product Properties**  
USA: NEMA 1, 4, 4X, 6, 12, 13  
EURO: IP 65 (EN 60529); IK 08 (EN 50102)

**MCE CONTROL**

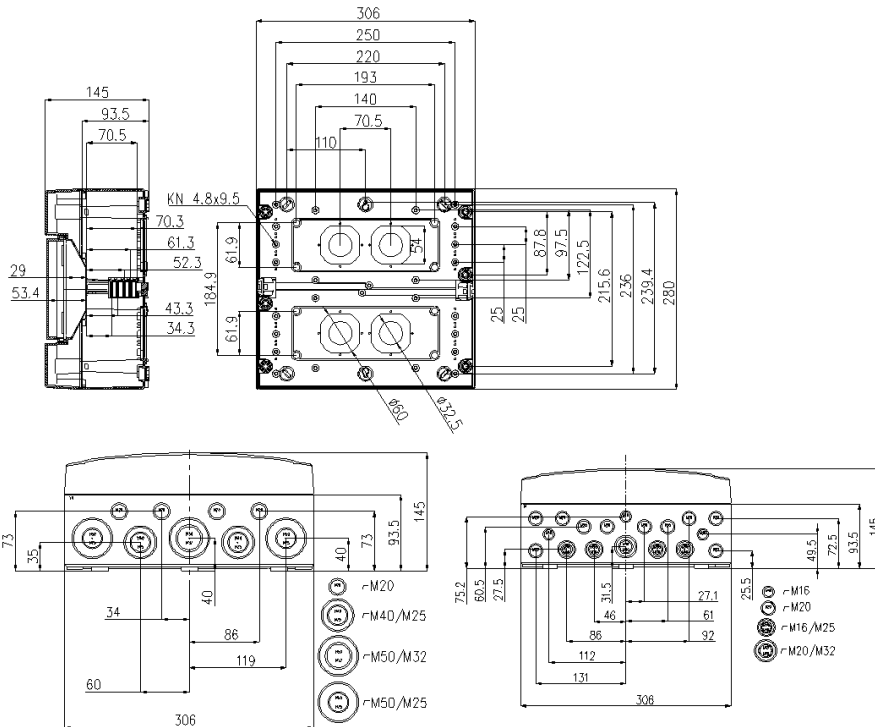

**Technical Information of Product Group**

Standard colour:	RAL 7035	Temp. range-in cont. use:	- 40° ... 80° C
Flame resistance:	UL-94 5 V	Temp. range-of material:	- 40° ... 120° C

**Accessories**

- Membrane cable gland FEM 26-35
- Membrane cable gland FEM 7-10
- Membrane cable gland MFM 8-12
- Membrane cable gland FEM 10-14/25
- Membrane cable gland FEM 14-20
- Membrane cable gland FEM 20-26
- Cover plug FEP 26150
- Lock MR 26065
- Sealing bushing DP 14553
- Multiadapter for PEN-bars MU 26138