

Identification

Part No.

Pg

Drawing

Dimensions in mm

Multiple seal

 
for Standard Hoods/Housings



09 00 000 5027
09 00 000 5028
09 00 000 5029
09 00 000 5030
09 00 000 5031
09 00 000 5032
09 00 000 5033

11
13,5
16
21
29
36
42

Ø	
min	max
7,5	12,5
7,5	12,5
7,5	15
10	19
18	27
24	33
30	39



for Hoods/Housings Han M



09 37 000 5027
09 37 000 5028
09 37 000 5029
09 37 000 5030
09 37 000 5031

11
13,5
16
21
29

7,5	12,5
7,5	12,5
7,5	15
10	19
18	27

Anti-twist device


for special metal cable clamp and hexagonal adaptor



09 36 000 9901
09 36 000 9902
09 36 000 9903
09 36 000 9904
09 36 000 9905

11
13,5
16
21
29

SW
20
22
24
30
41

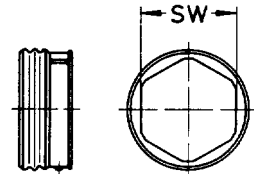

Cable sealing metal

with normal seal


for Standard Hoods/Housings



09 00 000 5113
09 00 000 5114
09 00 000 5115
09 00 000 5116
09 00 000 5117
09 00 000 5146
09 00 000 5119

11
13,5
16
21
29
36
42

SW	Ø
18	11
20	13
22	15
28	20
37	29
47	36
54	42

 

for Hoods/Housings Han M



09 37 000 5113
09 37 000 5114
09 37 000 5115
09 37 000 5116
09 37 000 5117

11
13,5
16
21
29

18	11
20	13
22	15
28	20
37	29

Cable sealing thermoplastic


with normal seal



grey
09 00 000 5164
black
09 00 000 5185

11
11

18	11
20	13
22	15
28	20
37	29

 

Cable sealing metal

with multiple seal


for Standard Hoods/Housings



09 00 000 5013
09 00 000 5014
09 00 000 5015
09 00 000 5016
09 00 000 5017
09 00 000 5018
09 00 000 5019

11
13,5
16
21
29
36
42

SW	Ø	
	min	max
18	7,5	12,5
20	7,5	12,5
22	7,5	15
28	10	19
37	18	27
47	24	33
54	30	39

 

for Hoods/Housings Han M



09 37 000 5013
09 37 000 5014
09 37 000 5015
09 37 000 5016
09 37 000 5017

11
13,5
16
21
29

18	7,5	12,5
20	7,5	12,5
22	7,5	15
28	10	19
37	18	27