

064 3214
316-337
3169.


Number of contacts
max. 64




Female connectors

Female connector
for crimp contacts
Order contacts
separately

09 02 064 3214

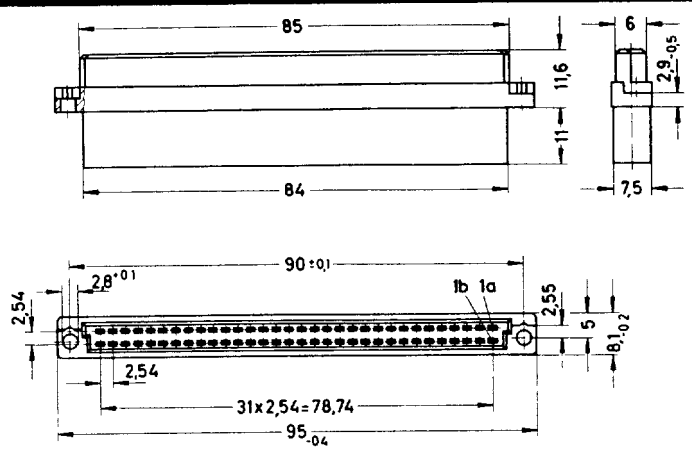

 Contact arrangement View from termination side



Shell housing 09 02 064 0501 / 09 02 064 0502 page 94

Female crimp
contacts

Bandoliered contacts
(approx 5000 pieces)

Individual contacts

09 02 000 6484

09 02 000 6474

09 02 000 6424

09 02 000 8484

09 02 000 8474

please
check change-over
to performance
level
1 or 2

09 02 000 6434

Wire gauge (mm²)
0.14-0.5

Insulation Ø
0.7-1.5

3.5 + 0.5 mm of insulation is stripped
from the wires to be crimped
Crimping tools page 90

