



Number of contacts

**64**

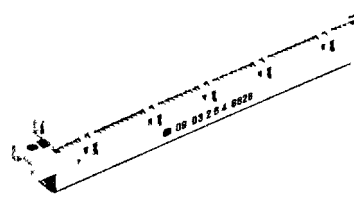

Female connectors

Identification	Number of contacts	Part No.	Drawing	Dimensions in mm
Female connector for insulation displacement	64	Performance level 2 09 03 264 6828		
		Performance level 3 09 03 264 7828		
Panel cut out			<p>View from termination side</p>	
Flat cable				
AWG 28/7				
grey	30.48 m	64	09 18 064 7003	<p>1) Termination area spacing = 508 mm</p>
grey	152.40 m	64	09 18 064 7004	
colour coded	30.48 m	64	09 18 064 7005	
twisted pair <sup>1)</sup>	30.48 m	64	09 18 064 7006	
Bench press			09 99 000 0114	
Base plate			09 99 000 0150	
Flat cable cutter			09 99 000 0116	
Spare parts				
Blade			09 99 000 0179	
Cutting plate			09 99 000 0180	

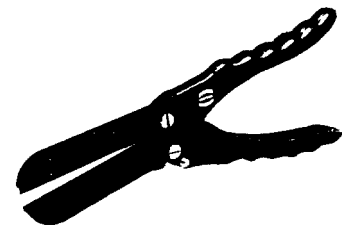

**Important:**  
always store reels vertically