




Home > Lampholders > Linear Fluorescent Lampholders: General Applications > G13 (Medium Bi-Pin): End Mount Lampholders

26.422.1113



◀ 1/1 ▶

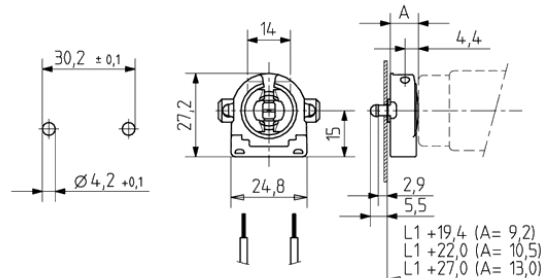

◀ 1/1 ▶

T130



Part No.	Color	Package qty.	Wt.
26.422.1113.50	white	500	7

- Rapid Start
- Snap-in pins with spring
- T-Marking: 130
- Top Test: yes
- Front Test: yes
- Material thickness: 0.5-1.1 mm
- Material thickness: 13 mm
- Wiring: through the body
- Rotor: with
 - Max. permissible temperature at Air-Pass Rotor (T): 130°C
 - Max. permissible temperature at rear of lampholder (Tm): 110°C
 - One lampholder with leaf spring provides a lamp length tolerance compensation of 2 mm
 - Lampholder body material: PC
 - cULus: File E-92235