



### KEB-3550

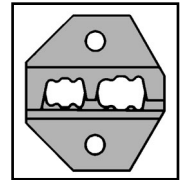

Die profile

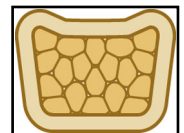

Crimp profile

The KEB-3550 is a precision, ratchet crimp tool designed to provide consistent and reliable crimp connections on endsplices/ferrules terminals on wires ranging from .

#### Easy to use

Open the tool. Insert terminal in correct nest. Close tool until terminal fastened. Insert wire into terminal. Close tool until ratchet release. Attention: To release ratchet mechanism, push the trigger.

#### Calibration

To calibrate this tool the pre-load has to be measured. Gauge is required to ensure that the die is according to specification. For more information; See instruction sheet.

- Professional crimp tool for optimized crimp performance.
- Ergonomic handles for low effort crimping.
- Ratchet action to ensure full crimp cycle with safety release.
- Durable - minimum of 50,000 cycles.
- Tool is factory set with a precise eccentric cam adjustment function to guarantee performance.

#### Technical data

Prod. code:	KEB-3550
Length:	255 mm / 10,04"
Height:	72 mm / 2,83"
Weight:	560 gr / 1,23 lbs
Connector:	Endsplices / Ferrules
Description:	Insulated and Uninsulated
Wire size:	2-01 AWG

Distributors address info