



SANDVIK BELZER

Double hexagon Inch



DIN 3124/ISO 2725.

3/8" ● 10 DIN 3120/ISO 1174.

Finish: nickel and chrome-plated, fine-polished.


 
Material: VANADIUM-EXTRA.

High performance sockets, thin-walled, with Dynamic-Drive-Profile.

Product code	EAN code 731415+		Dim. inch	L mm	D ₁ mm	D ₂ mm	T mm	
A7400DZ-1/4	1759193	5	1/4	28	9,5	17,2	6,5	15
A7400DZ-5/16	1759278	5	5/16	28	11,5	17,2	8,5	16
A7400DZ-3/8	1759438	5	3/8	28	13,5	17,2	10,5	19
A7400DZ-7/16	1759513	5	7/16	28	15,5	17,2	11,5	21
A7400DZ-1/2	1759780	5	1/2	28	17,5	17,2	12,5	22
A7400DZ-17/32	1819866	5	17/32	32	18,5	17,2	14,5	23
A7400DZ-9/16	1759865	5	9/16	32	19,5	17,2	14,5	25
A7400DZ-19/32	1819873	5	19/32	32	20,5	18	14,5	26
A7400DZ-5/8	1819880	5	5/8	32	21,4	19	14,5	28
A7400DZ-11/16	1819897	5	11/16	35	23,4	20,5	17	30
A7400DZ-3/4	1819903	5	3/4	35	25,4	22	17,5	40
A7400DZ-13/16	1819910	5	13/16	35	27,4	23,5	17,5	44
A7400DZ-7/8	1819927	5	7/8	38	29,4	24,5	19,5	50



A7400DZ

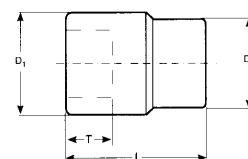


These sockets are applicable to all nuts and bolts used in the aerospace industry.

DIN	65546, 65438 - 65443,
LN	29520, 29542, 29550, 29551, 29769, 29901 - 29903, 29934, 29955, 65056, 65101 - 65106, 65416 - 65418, 29529, 29894, 29919, 65414,
VLN	29953,
EN	2907, 3013.

Dynamic-Drive-Profile

Low surface pressure due to large force-applying surfaces

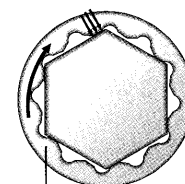

No notching sensitivity