



SANDVIK BELZER

Combination spanner, offset Metric

DIN 3113/ISO 3318

Finish: nickel and chrome-plated, fine polished.


 
Sizes 41 up to 60 mm nickel and chrome-plated.

Material: VANADIUM-EXTRA.

Open-end angle 15°, box end 10° offset, equal openings at both ends.

Dynamic-Drive-Profile up to 36 mm.


1952M

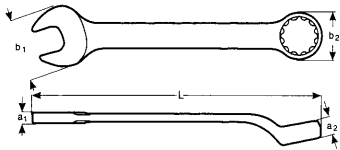

Product code	EAN code 731415+		Dim. mm	L mm	a ₂ x a ₁ mm	b ₂ x b ₁ mm	
1952M-6	1057176	10	6	100	4,5x 3,7	9,5x 14	15
1952M-7	1057183	10	7	110	5 x 3,8	11 x 16	19
1952M-8	1057190	10	8	120	5,5x 4,2	12,2x 18	23
1952M-9	1057206	10	9	130	6 x 4,5	13,2x 20	30
1952M-10	1057213	10	10	140	6,5x 4,8	14,6x 22	40
1952M-11	1057220	10	11	150	7 x 5	16,2x 24	49
1952M-12	1057237	10	12	160	7,5x 5,2	17,5x 26,5	61
1952M-13	1057244	10	13	175	8 x 5,6	19 x 28,5	68
1952M-14	1057251	10	14	185	8,5x 6	20 x 31	80
1952M-15	1057268	10	15	195	9 x 6,2	21,5x 33	100
1952M-16	1057275	10	16	205	9,8x 6,5	23 x 35	110
1952M-17	1057282	10	17	220	10,6x 7	24,5x 37	135
1952M-18	1057299	10	18	235	11,4x 7,2	26 x 39	155
1952M-19	1057305	10	19	250	12,2x 7,5	27 x 41,5	195
1952M-20	1057312	10	20	275	13,0x 8	28,5x 43,5	217
1952M-21	1057329	10	21	275	13 x 8	30 x 43,5	240
1952M-22	1057336	5	22	300	13,5x 8,5	32 x 48	297
1952M-23	1057343	5	23	300	13,5x 8,5	33 x 48	290
1952M-24	1057350	5	24	315	14,5x 9	34,5x 52	375
1952M-25	1057367	5	25	330	15,5x 9,5	36 x 54,5	400
1952M-26	1057374	5	26	330	15,5x 9,5	36,5x 54,5	400
1952M-27	1057381	5	27	350	16,5x10	38,5x 59	590
1952M-28	1057398	1	28	370	17 x10	40 x 61	700
1952M-29	1325763	1	29	370	17 x10	40 x 61	690
1952M-30	1057404	1	30	390	18 x10,7	42,5x 64	727
1952M-32	1057411	1	32	405	19 x11,5	45,5x 68	745
1952M-34	1838553	1	34	425	20 x12	48 x 72	800
1952M-36	1057428	1	36	475	21 x13,5	52 x 78	1230
1952M-41	1057435	1	41	510	24,4x14,4	61,5x 86,7	1350
1952M-46	1840105	1	46	520	25,4x15,4	67 x 93,6	1750
1952M-50	1840112	1	50	560	26,2x16,3	74,9x104,4	2200
1952M-55	1840129	1	55	570	28,6x19,1	82,7x113,3	3200
1952M-60	1840136	1	60	660	31 x20	90 x123	3600

Dynamic-Drive-Profile

Low surface pressure due to large force-applying surfaces

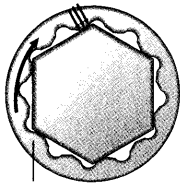

No notching sensitivity

DIN 3113/ISO 3318

Finish: nickel and chrome-plated.

Material: VANADIUM-EXTRA.

Open-end angle 15°, box end 10° offset, equal openings at both ends.
Dynamic-Drive-Profile.

Combination spanner, offset Metric

Product code	EAN code 731415+		No. units	Dim. mm	
--------------	---------------------	--	-----------	---------	--

In blue plastic wallet.

1952M/7T	1806637	1	7	8 10 13 14 17 19 22	820
1952M/14T	1057695	1	14	6 8 9 10 13 14 15 17 19 22 24 27 30 32	3500
1952M/17T	1057473	1	17	6 7 8 9 10 11 12 13 14 15 16 17 18 19 20 21 22	1900
1952M/26T	1057701	1	26	6 7 8 9 10 11 12 13 14 15 16 17 18 19 20 21 22 23 24 25 26 27 28 29 30 32	7000

In attractive sales cardboard box.

1952M/10	1057688	1	10	8 9 10 11 12 13 14 15 17 19	770
-----------------	---------	---	----	--------------------------------	-----

On functional plastic wall holder.

1952M/S12	1837587	1	12	8 9 10 11 12 13 14 15 16 17 18 19	1075
------------------	---------	---	----	--------------------------------------	------

1952M-Set

