
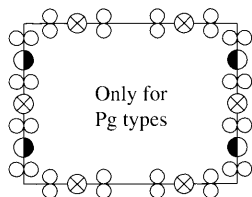
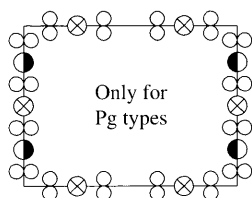
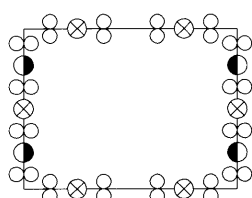
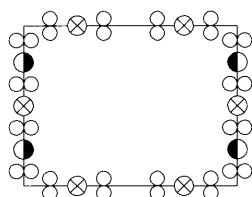


Type	Side Walls	Pg Knockouts	Inside Height	Ref. No.	Unit
POLYSTYRENE - COVER GREY RAL 7035					
PS 3625-11	with Pg		97 mm	115-412	3/1
PS 3625-16	with Pg		150 mm	115-912	2/1
PS 3625-21	with Pg		200 mm	114-412	1/1
PS 3625-11-o	smooth		97 mm	110-412	3/1
PS 3625-16-o	smooth		150 mm	110-912	2/1
PS 3625-21-o	smooth		200 mm	109-412	1/1
POLYSTYRENE - COVER TRANSPARENT					
PS 3625-11-t	with Pg		97 mm	116-012	3/1
PS 3625-16-t	with Pg		150 mm	116-512	2/1
PS 3625-21-t	with Pg		200 mm	117-012	1/1
PS 3625-11-to	smooth		97 mm	111-012	3/1
PS 3625-16-to	smooth		150 mm	111-512	2/1
PS 3625-21-to	smooth		200 mm	112-012	1/1
POLYCARBONATE - COVER GREY RAL 7035					
PC 3625-11	with Pg		97 mm	125-412	3/1
PC 3625-16	with Pg		150 mm	125-912	2/1
PC 3625-21	with Pg		200 mm	126-412	1/1
POLYCARBONATE - COVER TRANSPARENT					
PC 3625-11-t	with Pg		97 mm	135-012	3/1
PC 3625-16-t	with Pg		150 mm	135-512	2/1
PC 3625-21-t	with Pg		200 mm	136-012	1/1

TK 3625
Empty
Enclosure
361 x 254^{mm}
Type of
Protection
IP 66

Knockouts: ○ = Pg 16/11 ○ = Pg 16 ◐ = Pg 21/16 ⊗ = Pg 29/21

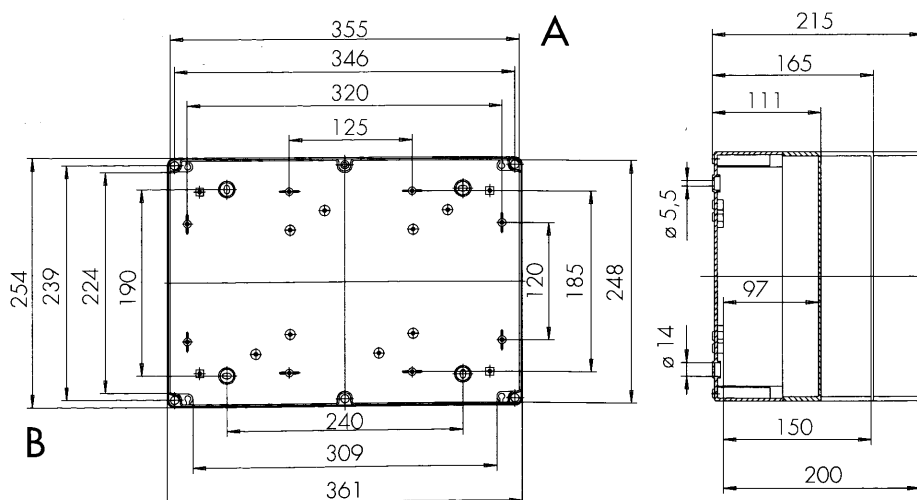

Max. number
of Pg drill holes
per box side

Pg	A	B
7	42	33
9	24	20
11	24	18
13.5	20	16
16	16	14
21	8	6
29	6	4
36	4	3

All dimensions in millimeters