



Coax Check®


Easy-to-read display! Local continuity tester for 50 and 75 ohm coaxial cables including RG58, RG59, RG62AU, RG6 AND RG6QS.

- Tests local coax patch cables
- Tests 50 ohm cables up to 1000 ft (305 meters) and 75 ohm cables up to 600ft (183 meters)
- Identifies open conductor, open shield/braid and shorted connections with simple Pass/Fail indicator
- Tests BNC-type, TNC-type, N- and C-type, and "F" connectors using BNC adapters
- BNC socket connection
- 9-volt battery included
- One-year warranty

Technical

Weight	5 oz. (140 g)
Dimensions	5.3" H x 2.8" W x 1" D (132 mm H x 71.2 mm W x 25 mm D)
Power reqs.	9VDC battery (one)
Output signal	8VDC@10mA

Ordering	Part Number
Coax-Check® tester	1560

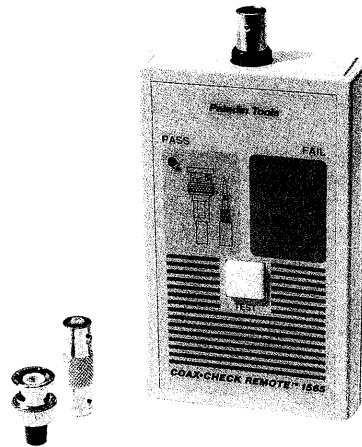

Coax Check® Remote


Test coax cables installed in walls! Remote continuity tester for 50 and 75 ohm coaxial cables including RG58, RG59 and RG62AU.

- Tests remote cables installed through walls
- Tests 50 ohm cables up to 1000ft (305 meters) and 75 ohm cables up to 600ft (183 meters)
- Tests N-type, TNC-type, C-type and "F" connectors using BNC adapters
- Identifies open conductor, open shield/braid and shorted connections with simple Pass/Fail indicator
- Includes 75 ohm BNC adapter and F/F BNC adapter
- BNC socket connection
- 9-volt battery included
- One-year warranty

Technical

Weight	5 oz. (140 g)
Dimensions	5.3" H x 2.8" W x 1" D (132 mm H x 71.2 mm W x 25 mm D)
Power reqs.	9VDC battery (one)
Output signal	8VDC@10mA

Ordering	Part Number
Coax-Check® Remote tester	1565

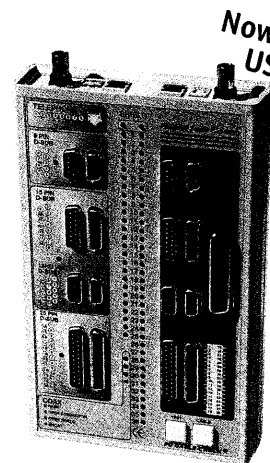

Now with USB!



PC Cable-Check®

Our most popular tester ... now with USB! Local tester for most computer cables including D-subminiature, coaxial, RJ11/RJ45 telephone cables and USB.

- Easy to use and read LED display
- Tests USB A to USB B
- Tests continuity of male and female 9-pin, 15-pin, 15-pin high density and 25-pin D-subminiature cables
- Tests continuity of: 36-pin Centronics printer cables, RJ11, RJ12 and RJ45 phone cables, and 50 and 75 ohm coaxial cables
- Tests D-sub and phone cables up to 1000 ft (305 meters)
- Tests 50 ohm cables up to 1000 ft (305 meters) and 75 ohm cables up to 600ft (183 meters)
- 9-volt battery included
- One-year warranty

Technical

Weight	24 oz. (630 g)
Dimensions	9.6" H x 5.4" W x 1.6" D (239 mm H x 137 mm W x 40 mm D)
Power reqs.	9VDC battery (one)
Output signal	8VDC@10mA

Ordering	Part Number
PC Cable-Check® tester	1570

394-5315