


**PRODUCT
DATA SHEET**

Type	Part No
Cold Cathode Fluorescent Lamp	HMBSM26205

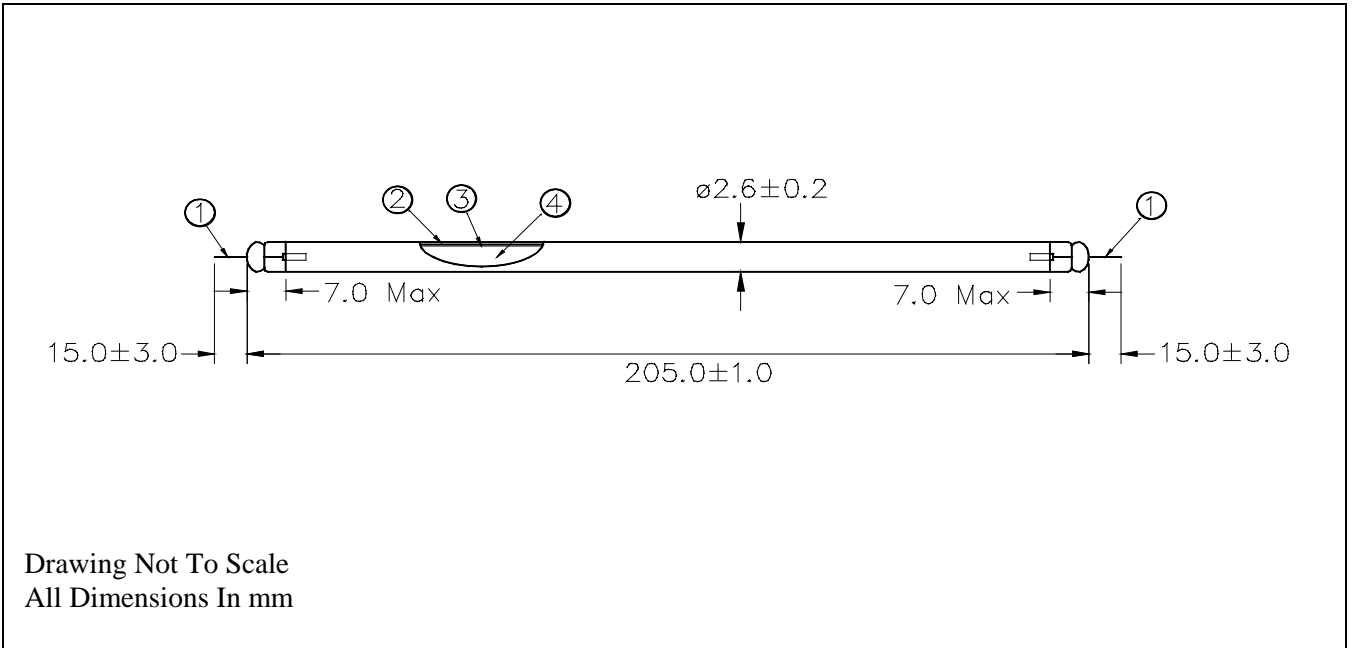

<u>Item No.</u>	<u>Description</u>
1	Dumet lead wires
2	Glass bulb
3	Phosphor
4	Gas (Neon/Argon)

LAMP DATA

Glass length:	205.0 ± 1.0mm
Glass diameter:	2.6 ± 0.2mm
Effective length:	183 mm min.
Lamp current:	5.0mA ± 0.5mA
Lamp voltage:	(500)V rms nom.
Brightness:	38,000 cd/m ² ± 15%
Colour Co-ordinates:	x 0.340 , y 0.358
Life:	25,000 hours min.

NOTES:

Full Part No: HMBSM26(N10W)205NLH/AXZ.

Issue No.	Date	C.N. No.	Drawn	Tech	QA	M & P	Sales
1	21/9/98		NR				