

365

SR1116W
Watch Battery
Swiss Made

Technical Data Sheet


Specifications

Chemical system	Zinc / Monovalent Silver Oxide, high drain
Nominal Voltage	1,55 V
Capacity	40 mAh, Discharge over 25,5 kΩ at 25°C to 1,2 V
Internal Resistance	Below 20 Ω at 25°C
Operating Temperature	0°C – 60°C
Self Discharge	Less than 5% per year at 20°C
Weight	~0,75 g

Dimensions


(according IEC 60086-3)

Diameter	11,60 mm (0,457")
Height	1,65 mm (0,065")

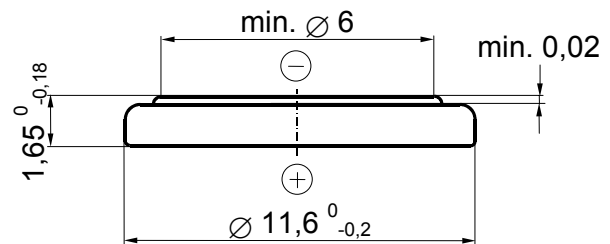

Discharge Curve

Constant Load	25,5 kΩ
Starting Drain	61,2 μA
Temperature	20°C

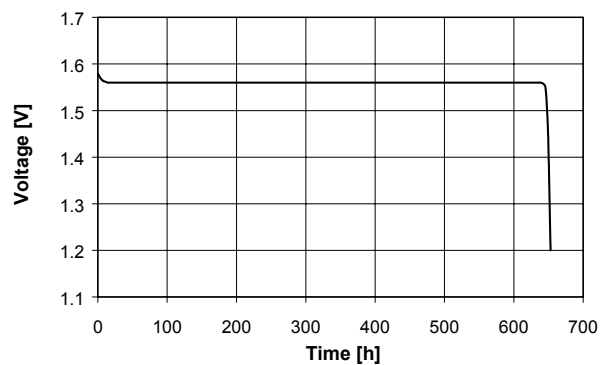

Rev. 365.03 06/02