


Manganese Dioxide Lithium Cylindrical Batteries: Individual Specifications


CR-V3p

■ Dimensions(mm)

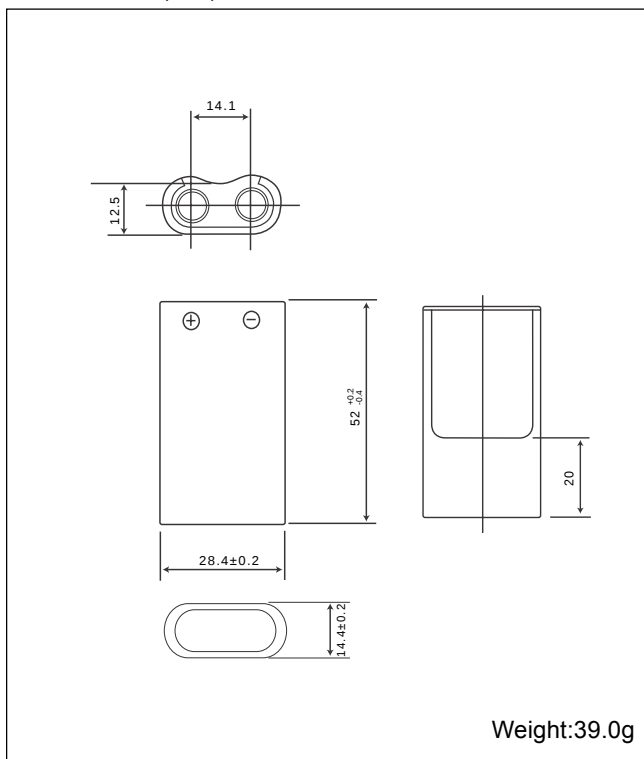

CR-V6p

■ Dimensions(mm)

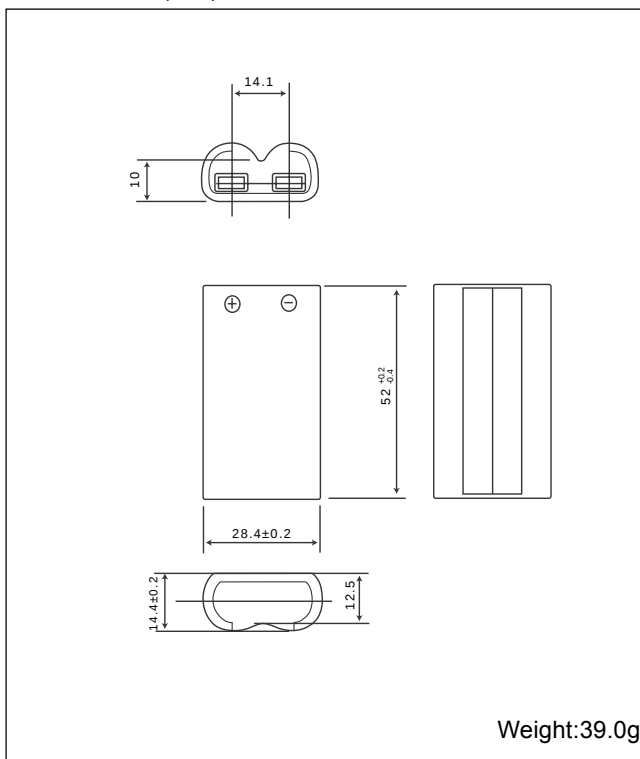


■ Specification

Nominal voltage (V)	3
Nominal capacity (mAh)	3,000
Continuous standard load (mA)	200
Operating temperature (C)	-40 ~ +70°


■ Specification

Nominal voltage (V)	6
Nominal capacity (mAh)	1,500
Continuous standard load (mA)	100
Operating temperature (C)	-40 ~ +70°

Discharge Characteristics of CR-V3p(2pc)and"AA"
Alkaline Cell (LR6,4pcs)

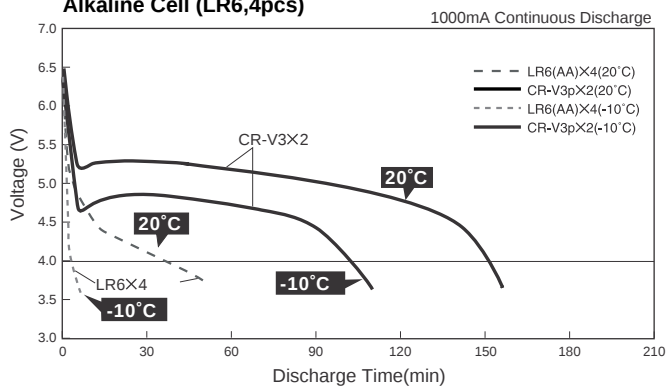

Discharge Characteristics of CR-V6p(1pc)and"AA"
Alkaline Cell (LR6,4pcs)

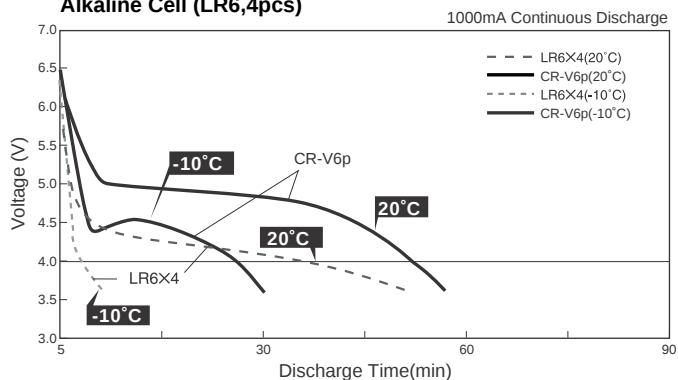

* Please consult Panasonic for use below and above -20°C to +60°C

* Please consult Panasonic for use below and above -20°C to +60°C