


Cable Ties & Bundling Systems

Military Specification Ties


- Lightweight, high strength fixings
- One piece, all plastic construction
- ISO 9002 approved
- Range of different materials available for high specification environments

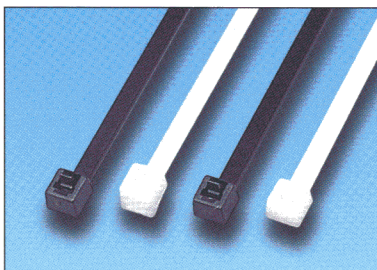


Military Specification Ties

Material - High grade Nylon 6.6

Product Reference	Overall Length mm	Strap Width mm	Minimum Tensile Strength		Maximum Cable Diameter mm	Recommended Tensioning Tool
			lbs	N		
T50S	150	4.8	50	222	36	MK3/MK20/MK7
T50R	200	4.8	50	222	50	MK3/MK20/MK7
T50M	250	4.8	50	222	65	MK3/MK20/MK7
T50I	300	4.8	50	222	81	MK3/MK20/MK7
T50L	385	4.8	50	222	107	MK3/MK20/MK7
T50LL	445	4.8	50	222	132	MK3/MK20/MK7

 

T80R	205	4.8	80	356	50	MK3/MK20/MK7/MK9
T80I	300	4.8	80	356	81	MK3/MK20/MK7/MK9
T80L	390	4.8	80	356	108	MK3/MK20/MK7/MK9

 

T120S	225	7.6	120	536	51	MK6/MK21/MK9
T120I	300	7.6	120	536	75	MK6/MK21/MK9
T120R	385	7.6	120	536	107	MK6/MK21/MK9
T120M	465	7.6	120	536	130	MK6/MK21/MK9
T120XM	610	7.6	120	536	170	MK6/MK21/MK9
T120L	760	7.6	120	536	220	MK6/MK21/MK9

