


PT-2730VP

TZ-Tape



Upon registration

Desktop Electronic Labeller

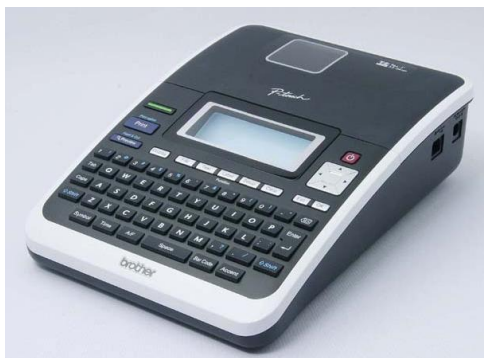

Copy

Ideal for all your office labelling needs, this feature-packed labeller can print a huge range of labels in different sizes. You can create your own styles or use one of the 55 pre-made designs in 18 languages with the Label Collection (or download even more), and to really speed things up it even remembers words you've typed before – perfect for organising even the busiest office!

Catalogue Spec

- Durable – labels up to 24mm, able to handle extreme conditions
- Space-saving compact, stylish design
- Easy to use QWERTY keyboard
- Preview your design easily with the large LCD screen
- Get creative, with customised labels printed direct from your PC
- Convenient automatic cutter for accurate label length
- Save time with up to 10mm per second printing
- Conveniently comes with 24mm black on white tape (8m)
- Extra versatility – print labels to 3.5, 6, 9, 12, 18 & 24mm

What's in the Box

- 1x 24mm Tape (as advised above)
- AD-24ES (Energy Star) Adapter
- Carry Case (Navy Blue)
- User Guide
- Software Installation Guide
- USB cable
- CD ROM

| INPUT DEVICE | |
|-----------------------------|--|
| Keyboard | QWERTY |
| DISPLAY | |
| Display | Graphic (16 chrs x 3 line) same as 2700 LCD |
| Language Support | English, German, French, Spanish, Portuguese, Italian, Dutch, Danish, Norwegian, Swedish, Finish, Hungarian, Czech, Polish, Romanian, Slovene, Slovak, Croatian, Turkish |
| PRINTING | |
| Print Height | 18.0 mm |
| Print Speed | 10 mm / sec |
| Print Resolution | 180 dpi / 128 dots |
| FEATURES | |
| Multi Line Printing | 7 lines |
| Multi Block Printing | Yes (Max. 5 blocks) |
| Copy Printing | Yes (1-99) |
| Bar Code | Yes (9kinds) |
| Mirror Printing | Yes |
| Numbering | Yes (1-99) |
| Vertical Printing | Yes (in the style setting) |
| Underline | Yes (underline / strikethrough) |
| Framing | 20 kinds |
| Font variations | 8 kinds (Helsinki/Brussels/US/LosAngeles/San Diego/Florida/Calgary/Belgium) |
| Font style variations | 10 kinds (Normal/Bold/Outline/Shadow/Solid/Italic/Italic Bold/Italic Outline/ Italic Shadow/Italic Solid/Vertical) |
| Font size variations | 8 kinds (Auto/6/9/12/18/24/36/42/48pt) |
| Font width variations | 5 kinds (x1/2, x2/3, x1, x3/2, x2) |
| Number of Characters | 462 |
| Number of Symbols | 253 |
| Number of Auto Formats | 42 |
| Tape Cut | Auto |
| Preview | Yes |
| Label Length Setting | Yes (30 - 300mm) |
| Label Collection | 55 kinds |
| Label Collection DL Feature | Yes *Can add 20 files |
| DECO MODE | No |
| Text Reminder | Yes |
| Time & Date | Yes |
| MEMORY | |
| Memory | 2,800 characters (99 areas) |
| POWER SUPPLY | |
| Power Supply | AAA x 8 pcs |
| | AC adapter AD-24ES |
| SIZE | |
| Dimensions | 70mm (H) x 177 (W) x 238mm (D) |
| Weight | 0.88kg |
| SUPPLIES | |
| Tape Cartridge | TZ Tape |
| Tape width variations | 3.5, 6, 9, 12, 18, 24mm |
| PC CONNECTION | |
| Operating System | Windows / Mac |
| Interface | Yes |
| Label Editing Software | P-touch Editor 5.0 |