


19" RACK 2u HORIZONTAL


UK Style 13 amp 250v

Horizontal PDU's incorporating front facing brackets for rack mounting.
RPP's 2u Height Power Distribution Units are designed for use in 19" Data Cabinets.

- 230v a.c. only.
- 13 amp maximum.
- Plug and sockets to BS 1363, fuses to BS1362.

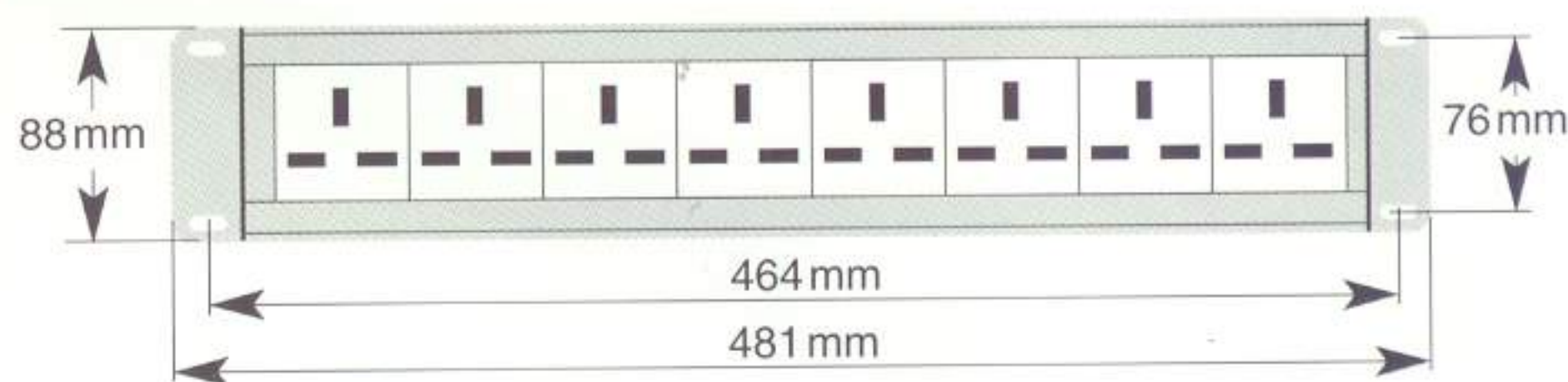

The 19" width permits the use of up to 8 socket ways per unit per any socket type.

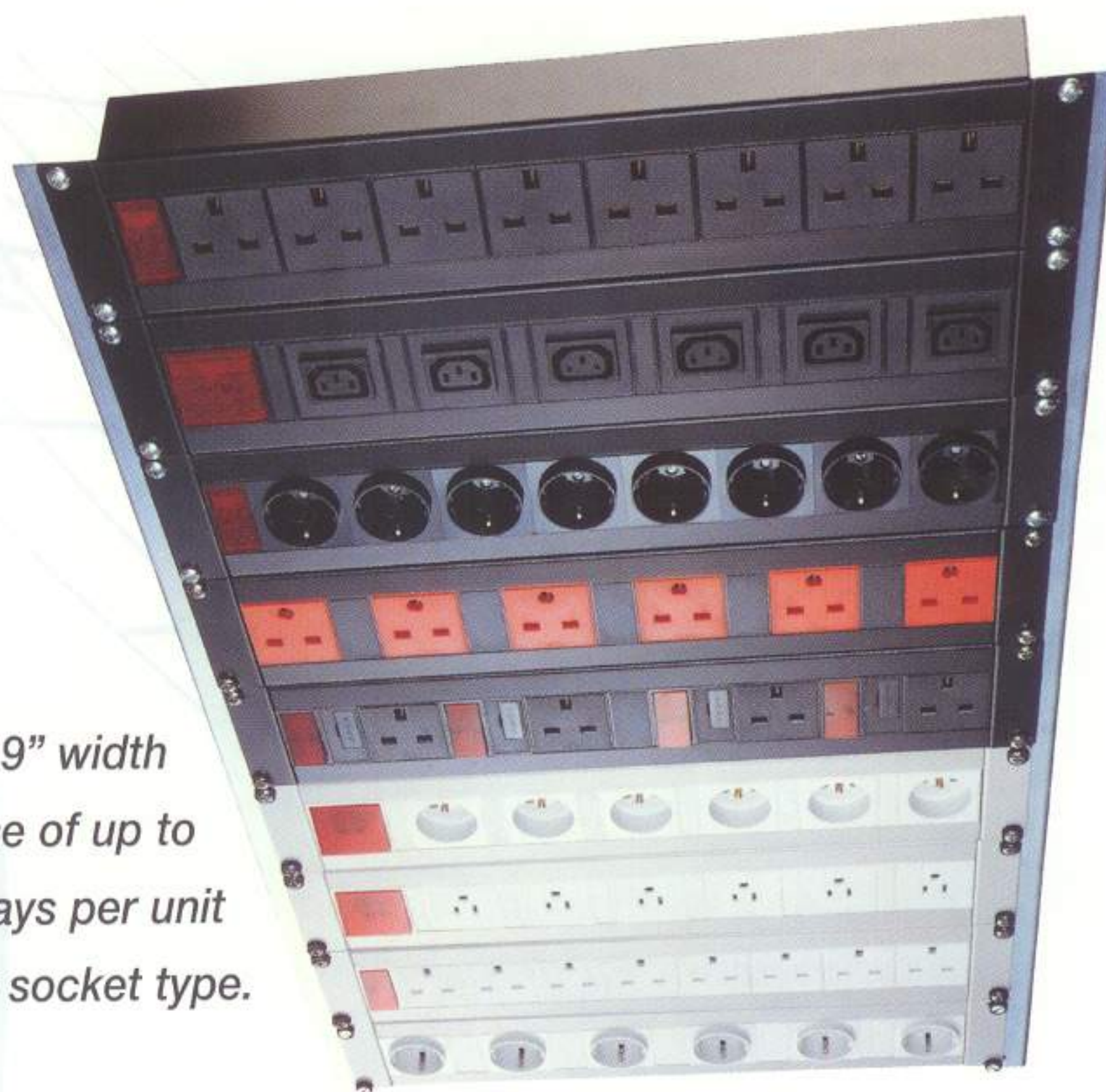

*NB Maximum number of sockets is six if RCD, RCBO, or Filter options are chosen

Example Order Code:- X2U4 S F BK = 4 Way • Switch • Filter • Black


Available options	S	N	F*	SCH	USA	FRE	E	Z	G	D*	C*	U	BK	16	32
16 AMP DOUBLE POLE ILLUMINATED SWITCH	NEON INDICATOR ONLY	10 AMP RFI / TRANSIENT SUPPRESSOR FILTER	16 AMP CEET SCHUKO SOCKET	15 AMP AMERICAN SOCKET	16 AMP FRENCH / BELGIAN SOCKET	IEC 60320 10 AMP SOCKET	13 AMP UK NON-STANDARD SOCKET	SURGE PROTECTION MODULE	RCD	RCBO	13 AMP FUSE MODULE	ALL BLACK	16 AMP PLUG	32 AMP PLUG	

RPP 2U Height Power Distribution Units are designed for use in 19" Data Cabinets

X2U4	2U 4 WAY UNSWITCHED
X2U5	2U 5 WAY UNSWITCHED
X2U6	2U 6 WAY UNSWITCHED
X2U7	2U 7 WAY UNSWITCHED
X2U8	2U 8 WAY UNSWITCHED
X2U4S	2U 4 WAY SWITCHED
X2U5S	2U 5 WAY SWITCHED
X2U6S	2U 6 WAY SWITCHED
X2U7S	2U 7 WAY SWITCHED
X2U8S	2U 8 WAY SWITCHED

Replace "S" with "N" if a neon indicator only is required

X2U4F	2U 4 W	AY UNSWITCHED + FILTER
X2U5F	2U 5 W	AY UNSWITCHED + FILTER
X2U6F	2U 6 W	AY UNSWITCHED + FILTER
X2U4SF	2U 4 W	AY SWITCHED + FILTER
X2U5SF	2U 5 W	AY SWITCHED + FILTER
X2U6SF	2U 6 W	AY SWITCHED + FILTER

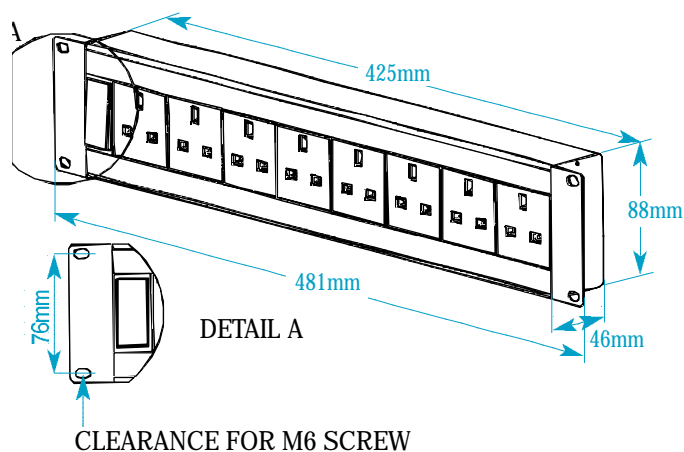

230V a.c. only
13amp max
Plug and sockets to BS1363
Fuses to BS1362

International Sockets

- For Schuko sockets suffix SCH (e.g. X2U4/SCH)
- For French/Belgian sockets suffix FRE (e.g. X2U4/FRE)
- For American socket suffix USA (e.g. X2U4/USA)
- For IEC 320 sockets suffix IEC (e.g. X2U4/IEC)
- Switched versions fitted with a 16 amp double pole illuminated switch

Filter Technical Data

- Operating Voltage up to 250V at max 400HZ
- Rated current 10 amps @ 40°C, 11.5 amps @ 25°C
- Leakage current @ 220V 50HZ max. 2 x 0.2mA
- The filters are fitted with ZNR voltage Transients and Earthline choke.

Standard Spec. Z280G

- Max Cont. Volts AC RMS @ 25°C.....320
- Max Cont. Volts DC @ 25°C.....416
- Varistor V Min @ 1mA.....450
- Energy Joules 10/1000 amps.....140
- Clamping Volt @ 100 amps.....825
- m Watts Cont.....800

- Polycarbonate accessories in an aluminium body - a robust combination.
- 2 metre fitted plug and lead set as standard. Other lengths can be supplied.

For further information or our comprehensive accessory brochure please contact RPP Sales.



RPP, Pipers Road, Park Farm Industrial Estate,
Redditch, Worcestershire, United Kingdom B98 0HU
Telephone: 0044 (0)1527 528024
Fax: 0044 (0)1527 520236

