


RMX Series



- RMX-06
- RMX-12Y

- High SPL
- Through Hole Design
- Top Sound Hole
- Dip Solderable and Washable

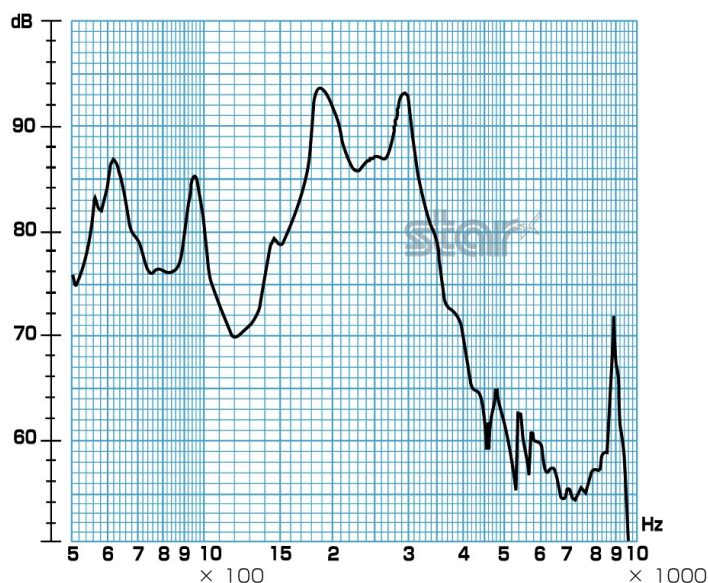

Specifications:

	RMX-06	RMX-12Y
SPL	Min. 85 dB Typ. 93 dB	
Rated Voltage	6 V _{p-p}	12 V _{p-p}
Rated Frequency	2,048 Hz	
Mean Current Consumption	Max 40 mA	
Operation Temp.	-40°C to +85°C	
External Size	φ16mm x 14mm	
Mass	5g	

