


PPC204

1 PORT RS232 / 1 PORT LPT

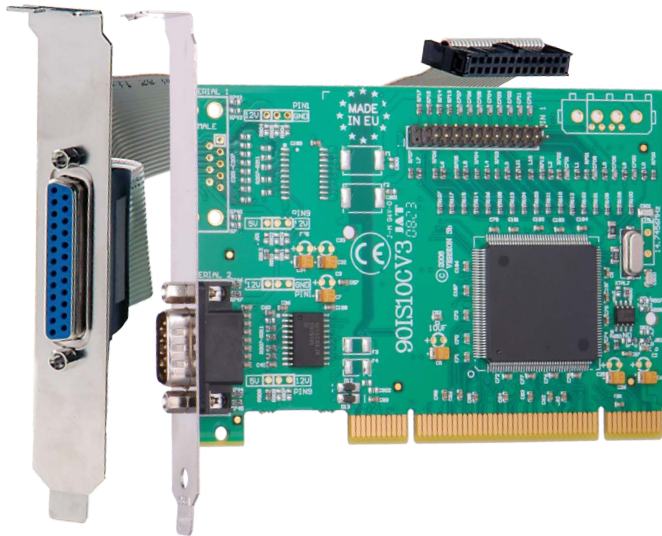

pro-SIGNAL



PRODUCT INFORMATION

This card provides 1 industry standard 9 pin RS232 serial COM port in a single PCI slot. By adding the LPT adapter cable, a parallel printer port becomes available.

As PCI is fully Plug & Play compatible the operating system or BIOS automatically configures the card ensuring conflict free installation.

OPERATING SYSTEMS:

Windows 7 32bit & 64bit
Windows Vista 32bit & 64bit
Windows XP 32bit & 64bit
Windows Server 2003 & Windows Server 2008
Windows 2000



PRODUCT FEATURES:

- 1x9 pin, D type RS232 Serial Port
- 1 LPT Port on adapter cable
- PCI Bus - Fully Plug & Play
- PCI 2.3 Compliant
- 16 Byte transmit and receive FIFO
- Supports both 3.3V / 5V standards
- Drivers for all popular operating systems
- Test software provided
- Install guide, FAQ and other support documents provided
- 3 years Warranty

SPECIFICATIONS:

- Serial Ports: 1x9 pin, D type RS232 Serial Port
- Parallel Ports: 1
- UART: 16550
- Speed: 115,200 maximum baud rate
- Data Bits: 5, 6, 7 or 8
- Stop Bits: 1 or 2
- Parity: odd, even, none, mark or space
- FIFO Size: 16 byte
- Bus type: 32-bit PCI
- IRQs: Plug and play - Shared interrupts for all ports



Pro-Signal uPCI 1 PORT RS232 / 1 PORT LPT*

PRODUCT CODE: PPC204

*LPT cable included



pro-SIGNAL