

3M Fibre Connectivity

Coloured Pigtail Modules

Preliminary



These coloured pigtailed complement the use of colour coded fibre in loose tube cables. Usually 12 different colours are used in either IEC or Bellcore coding. These pigtailed use the same 12 colours, thus can be used for applications with both colour codes. The use of these colour coded pigtailed makes the termination of fibre cable in patch panels or termination terminals easier and safer. Due to clear dedications, the risk of wrong fibre connections is reduced.

Two times 6 each semi.tight buffered pigtailed in different standard colours are wrapped around two cardboard carriers and packed in a plastic bag.

Features


- Wrapped around cardboard carrier
- 12 different colours
- For all commonly used connector types

Benefits


- More convenient fibre management
- Easier connection to backbone cable
- Universal solution for all fibre patch panels

Specifications:

Pigtail length :	2m
Pigtail colours IEC 304 :	Red, green, blue, yellow, white, grey, brown, violet, aqua, black, orange, rose
Pigtail type:	900µm Semi-tight buffer

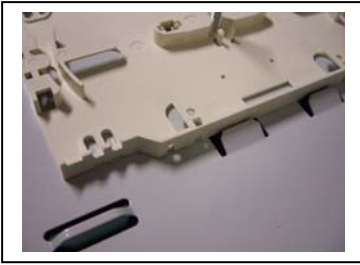

Perfect fit to 3M Eco patch panels but fits any other 19" panel as SPP3-E type

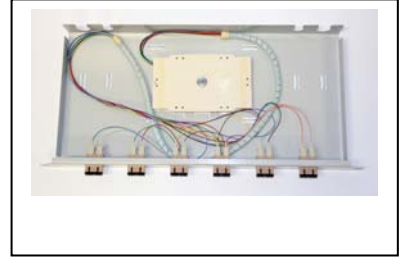

Ordering Information

Description

ST Pigtail Multimode 50/125, 2m, 12 each in different IEC colour code
 ST Pigtail Multimode 62,5/125, 2m, 12 each in different IEC colour code
 SC Pigtail Multimode 50/125, 2m, 12 each in different IEC colour code
 SC Pigtail Multimode 50/125, 2m, OM3, 12 each in different IEC colour code
 SC Pigtail Multimode 62,5/125, 2m, 12 each in different IEC colour code
 SC Pigtail Single-mode 9/125, 2m, 12 each in different IEC colour code
 SC/UPC Pigtail Single-mode 9/125, 2m, 12 each in different IEC colour code
 LC Pigtail Multimode 50/125, 2m, 12 each in different IEC colour code
 LC Pigtail Multimode 50/125, 2m, OM3, 12 each in different IEC colour code
 LC Pigtail Multimode 62,5/125, 2m, 12 each in different IEC colour code
 LC Pigtail Single-mode 9/125, 2m, 12 each in different IEC colour code
 LC/UPC Pigtail Single-mode 9/125, 2m, 12 each in different IEC colour code
 FC Pigtail Single-mode 9/125 yellow, 2m, 12 each in different IEC colour code

MOQ/each

6/bag/2bags/Carton
 6/bag/2bags/Carton
 6/bag/2bags/Carton
 6/bag/2bags/Carton
 6/bag/2bags/Carton
 6/bag/2bags/Carton
 6/bag/2bags/Carton
 6/bag/2bags/Carton
 6/bag/2bags/Carton
 6/bag/2bags/Carton
 6/bag/2bags/Carton
 6/bag/2bags/Carton
 6/bag/2bags/Carton
 6/bag/2bags/Carton

Ref.












BANOO-ZK0002-CC
BANOO-AP0002-CC
BDBOO-ZK0002-CC
BDBOO-ZO0002-CC
BDBOO-AP0002-CC
ADAOO-AU0002-CC
AEQOO-AU0002-CC
BDUOO-ZK0002-CC
BDUOO-ZO0002-CC
BDUOO-AP0002-CC
ADVOO-AU0002-CC
ADQOO-AU0002-CC
AENOO-AU0002-CC

Packaging



Two bags in one box are the MOQ of 12 coloured pigtails

Ordering Information Accessories (not included)

	Description	MOQ/each	Ref. No.
	LWL-Spleißkassette inkl. Zugentlastung, div. Kabelbindern, ohne Spleißschutzhalter Maße: 155 x 92 x 8 mm (HxBxT) Farbe: RAL 9001 (cremeweiß), VPE: 10 Stück		29026-500 31
	LWL-Spleißkassette inkl. Spleißschutzhalter für 12x Crimpspleißschutz und div. Kabelbindern, ohne Zugentlastung Maße: 155 x 92 x 8 mm (HxBxT) Farbe: RAL 9001 (cremeweiß), VPE: 30 Stück		29026-500 30
	LWL-Deckel für Spleißkassette, Farbe: RAL 9001 (cremeweiß) Maße: 155 x 92 x 2 mm (HxBxT) VPE: 10 Stück VPE: 50 Stück		29025-503 31 29025-503 30
	DIN Spleißkassette Scharnier rot zum Verbinden von Spleißkassette und Deckel		03-756-00500
	LWL-Zugentlastung für 12 Fasern mit Ø 0.9 und 1.1 mm Coating VPE: 50 Stück		29031-000 30
	LWL-Spleißschutzhalter Crimp VPE: 10 Stück, für 12x Crimpspleißschutz		05-760-08000
	LWL-Crimpspleißschutz VPE: 150 Stück		05-760-08100
	LWL-Spleißschutzhalter Heißschrumpf VPE: 10 Stück, für 6x Schrumpfspleißschutz		05-760-11900
	LWL-Heißschrumpfspleißschutz 60 mm VPE: 100 Stück		05-760-12000
	LWL-Heißschrumpfspleißschutz 45 mm VPE: 100 Stück		05-760-12100
	LWL-Spleißschutzhalter Fibrlok™ Universal VPE: 20 Stück, für 6x FibrLok		2529-H

3M

3M Telecommunications

Europe, Middle East & North Africa

c/o Quante AG

Carl-Schurz-Staße 1 • 41453 Neuss • Germany

Tel: ++49 (0)2131 / 14-5999

Fax: ++49 (0)2131 / 14-5998

Internet: www.3MTelecommunications.com