

Northern UK Sales - Tel +44 (0)1909 569446

Southern UK Sales - Tel +44 (0)1243 871280

Export Sales - Tel +44 (0)1243 871287

Email [sales@labfacility.co.uk](mailto:sales@labfacility.co.uk)

Celebrating 40 years in  
Temperature Measurement  
1971 - 2011



Sensor + Test Show 2011  
Nuremberg, Germany  
Visit Us at Stand 12 - 553



Home

Thermocouple Cables

Thermocouple Connectors

Temperature Instrumentation

Temperature Sensors

Calibration



## Thermocouple Connectors

- Standard
- Miniature
- Panel <<
- Terminal Strip

- Accessories
- Thermocouple Cables
  - PVC Insulated
  - PFA & PTFE Insulated
  - Glassfibre Insulated
  - PRT Sensor Cables
- Temperature Instrumentation
  - Tempmaster PRO
  - Labcal PRO
  - Fine Wire Welder
  - L200 Temperature Monitor
- Temperature Sensors
  - Thermocouples
  - Platinum Resistance Thermometers
  - Temperature Transmitters
  - Sensor Accessories
  - Custom Built Sensors
- Calibration

[Home](#) > [Temperature Products](#) > [Thermocouple Connectors](#) > Panel Thermocouple Connectors

# Panel Thermocouple Connectors

---



## Standard Rectangular Facia Socket Thermocouple Connectors

- Quick, simple fixing to panel
- Clip mounting
- Maximum continuous operating temperature 120°C

Type	Part No. (Socket)	Colour
Copper	IS-Cu-FF	
E	IS-E-FF	
J	IS-J-FF	
K	IS-K-FF	
N	IS-N-FF	
R/S	IS-R-FF	
T	IS-T-FF	

Download	Type
Connectors & Accessories Brochure	
Schematic Drawing	




Further Information
<a href="#">Send Enquiry</a>
Call +44 (0)1909 569446 <a href="mailto:sales@labfacility.co.uk">sales@labfacility.co.uk</a>



## Standard Panel Mount Stainless Steel Bracket Thermocouple Connectors

- These standard sockets supplied with stainless steel brackets allow reliable fitting into panels
- Rugged fitting into panel
- Quick, simple fixing to connector
- Maximum continuous operating temperature 220°C

Type	Part No. (Socket)	Colour
Copper	IS-Cu-SSPF	
E	IS-E-SSPF	
J	IS-J-SSPF	
K	IS-K-SSPF	
N	IS-N-SSPF	
R/S	IS-R-SSPF	
T	IS-T-SSPF	

Download	Type
Connectors & Accessories	
Brochure	
Schematic Drawing	

Further Information

[Send Enquiry](#)

Call +44 (0)1909 569446  
[sales@labfacility.co.uk](mailto:sales@labfacility.co.uk)



## Panels for Standard Facia Sockets (Type FF)

- Formula for dimensions :  
 Length = (Nx19)+31mm (N=Number of ways per row)
- Height = 66mm (Single row), 111mm (Double row)
- Up to 12 ways in a single row, 16 to 24 ways in two rows

Type	Part No.	Type	Part No.
1 Way	FSP-1	24 Way	FSP-24
10 Way	FSP-10	3 Way	FSP-3
12 Way	FSP-12	4 Way	FSP-4
16 Way	FSP-16	5 Way	FSP-5
18 Way	FSP-18	6 Way	FSP-6

2 Way	FSP-2	8 Way	FSP-8
20 Way	FSP-20		








Download	Type
Connectors & Accessories Brochure	



Further Information
<a href="#">Send Enquiry</a>
Call +44 (0)1909 569446 <a href="mailto:sales@labfacility.co.uk">sales@labfacility.co.uk</a>



## Miniature Rectangular Fascia Socket Thermocouple Connector

- Clip mounting
- Quick, simple fixing to panel
- Maximum continuous operating temperature 120°C

Type	Part No. (Socket)	Colour
Copper	IM-Cu-FF	
E	IM-E-FF	
J	IM-J-FF	
K	IM-K-FF	
N	IM-N-FF	
R/S	IM-R-FF	
T	IM-T-F	

Download	Type
Connectors & Accessories Brochure	
Schematic Drawing	

## Further Information








[Send Enquiry](#)

Call +44 (0)1909 569446

[sales@labfacility.co.uk](mailto:sales@labfacility.co.uk)

## Miniature Panel Mount Stainless Steel Bracket Thermocouple Connector

- Miniature sockets supplied with stainless steel brackets
- Allow reliable, rugged fitting into panel
- Quick, simple fixing to panel
- Maximum continuous operating temperature 220°C

Type	Part No. (Socket)	Colour
Copper	IM-Cu-F	
E	IM-E-F	
J	IM-J-F	
K	IM-K-F	
N	IM-N-F	
R/S	IM-R-F	
T	IM-T-F	

Download

Type

Connectors &amp; Accessories

Brochure



Schematic Drawing



## Further Information

[Send Enquiry](#)



 





Call +44 (0)1909 569446


[sales@labfacility.co.uk](mailto:sales@labfacility.co.uk)



## Miniature Quick Wire Stainless Steel Bracket Thermocouple Connector

- Miniature sockets supplied with stainless steel brackets
- Allow reliable, rugged fitting into panel
- Quick, simple fixing to panel
- Maximum continuous operating temperature 220°C

Type	Part No. (Socket)	Colour
Copper	IM-Cu-SSPF	
E	IM-E-SSPF	
J	IM-J-SSPF	
K	IM-K-SSPF	
N	IM-N-SSPF	
R/S	IM-R-SSPF	 
T	IM-T-SSPF	

Download	Type
Connectors & Accessories Brochure	

Further Information
<a href="#">Send Enquiry</a>
Call +44 (0)1909 569446 <a href="mailto:sales@labfacility.co.uk">sales@labfacility.co.uk</a>









## Miniature PCB Mounting Socket Thermocouple Connector

- Versatile, high quality, circuit board mounting miniature socket
- Specially designed for PCB's


## Panel Thermocouple Connectors

- Solid pins for direct PCB mounting
- Provision for CJC sensor
- Compatible with flow soldering assembly
- Maximum continuous operating temperature 220°C

Type	Part No. (Socket)	Colour
Copper	IM-Cu-PCBF	
K	IM-K-PCBF	
T	IM-T-PCBF	

Download	Type
Connectors & Accessories	
Brochure	
Schematic Drawing	

Further Information
<a href="#">Send Enquiry</a>
Call +44 (0)1909 569446 <a href="mailto:sales@labfacility.co.uk">sales@labfacility.co.uk</a>

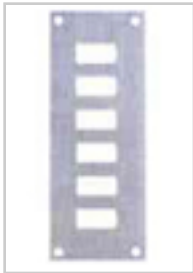


## Panels for Miniature Fascia Sockets (Type FF)

- Formula for dimensions :  
Length = (N×15)+25mm (N=Number of ways per row)
- Height = 45mm (Single row), 75mm (Double row)
- Up to 12 ways in a single row, 16 to 24 ways in two rows

Type	Part No.	Type	Part No.
1 Way	FMP-1	24 Way	FMP-24
10 Way	FMP-10	3 Way	FMP-3
12 Way	FMP-12	4 Way	FMP-4
16 Way	FMP-16	5 Way	FMP-5
18 Way	FMP-18	6 Way	FMP-6
2 Way	FMP-2	8 Way	FMP-8
20 Way	FMP-20		



Download	Type
Connectors & Accessories Brochure	

Further Information
<a href="#">Send Enquiry</a>
Call +44 (0)1909 569446 <a href="mailto:sales@labfacility.co.uk">sales@labfacility.co.uk</a>

- [Home](#)
  - [Contact Us](#)
  - [About Labfacility](#)
  - [News](#)
- [Thermocouple Cables](#)
  - [PVC Insulated](#)
  - [PFA & PTFE Insulated](#)
  - [Glassfibre Insulated](#)
  - [PRT Sensor Cables](#)
- [Thermocouple Connectors](#)
  - [Standard](#)
  - [Miniature](#)
  - [Panel](#)
  - [Terminal Strip](#)
  - [Accessories](#)
- [Temperature Instrumentation](#)
  - [Tempmaster PRO](#)
  - [Labcal PRO](#)
  - [Fine Wire Welder](#)
  - [L200 Temperature Monitor](#)
- [Temperature Sensors](#)
  - [Thermocouples](#)
  - [Platinum Resistance Thermometers](#)
  - [Temperature Transmitters](#)
  - [Sensor Accessories](#)
  - [Custom Built Sensors](#)
- [Calibration](#)

- 
- [Product Information](#)
- [Knowledge Base](#)
- [Temperature Handbook](#)
- [Downloads](#)

Northern Sales: 0190 956 9446 - Southern Sales: 0124 387 1280 - Export Sales: +44 (0)1243 871287 - [sales@labfacility.co.uk](mailto:sales@labfacility.co.uk) - Copyright © 2011 -  
Labfacility Limited - [Internet Strategy](#) by Lexiconnect Limited

