
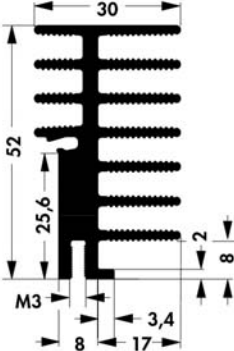
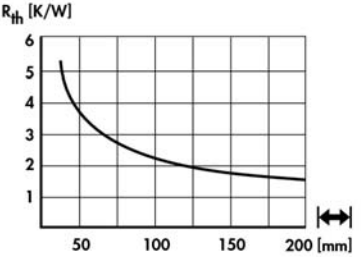
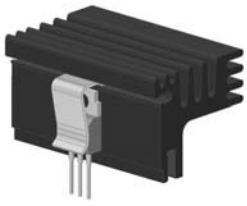
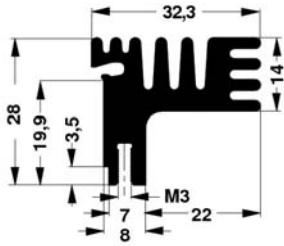
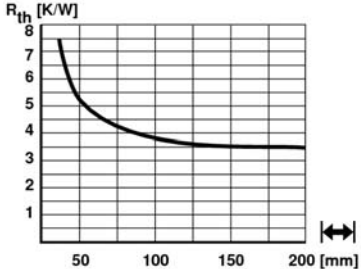
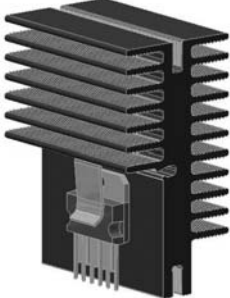
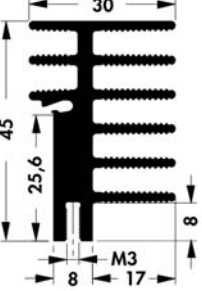
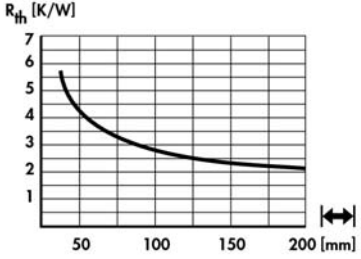

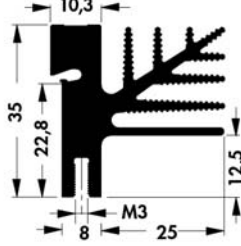
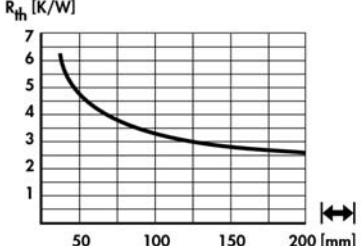


Extruded heatsinks for lock-in retaining spring

art. no. SK 514 ...			
please indicate: ... $\left[\text{mm} \right]$ 25 37.5 50 75 100 1000 mm			
art. no. SK 574 ...			
please indicate: ... $\left[\text{mm} \right]$ 25 37.5 50 75 84 100 1000 mm			
art. no. SK 589 ...			
please indicate: ... $\left[\text{mm} \right]$ 25 37.5 50 75 84 100 1000 mm			
art. no. SK 482 ...			
please indicate: ... $\left[\text{mm} \right]$ 25 37.5 50 75 84 100 1000 mm			

please note: profile threads → A 4