
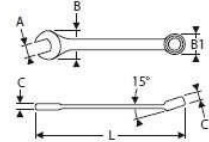


COMBINATION WRENCHES - METRIC

- ISO 691 - ISO 1711-1 - ISO 3318 - ISO 7738 - DIN 3113
- 12-point OGV® ring angled at 15°.
- Open end angled at 15° from handle axis.
- OGV® profile maximizing the contact surface with the nut for a longer lifetime.
- Forged in Chrome Vanadium steel.
- High chrome finish.

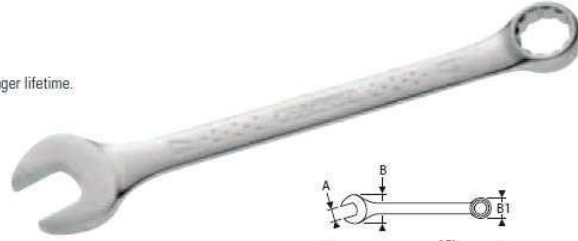

	A (mm/°)	L (mm)	B (mm)	B1 (mm)	C (mm)	C1 (mm)	Weight (g)		EAN	List Price
E113228B	5	93	14,70	9,80	3,40	4	15	1	3258951132289	
E113229B	5,5	93	14,70	9,80	3,40	4	15	1	3258951132296	
E113202B	6	100	16,20	10,40	3,70	4,50	20	1	3258951132029	
E113200B	7	110	18,20	11,70	3,70	5	20	1	3258951132005	
E113201B	8	120	20,20	13,20	4,10	5,10	25	1	3258951132012	
E113204B	9	130	22,20	14,60	4,10	6	35	1	3258951132043	
E113205B	10	140	23,70	16,00	4,60	6,50	37	1	3258951132050	
E113206B	11	150	25,70	17,60	4,70	6,50	45	1	3258951132067	
E113207B	12	160	27,50	19,00	4,80	7	60	1	3258951132074	
E113208B	13	170	29,70	20,60	5,50	7,50	67	1	3258951132081	
E113209B	14	180	31,70	22,00	5,60	8	80	1	3258951132098	
E113210B	15	190	34,20	23,40	5,70	8,50	95	1	3258951132104	
E113211B	16	200	36,20	24,80	5,80	9	110	1	3258951132111	
E113212B	17	210	38,50	26,20	6,30	9,50	123	1	3258951132128	
E113213B	18	220	39,20	27,60	6,80	10	150	1	3258951132135	
E113214B	19	230	42,20	29,00	7,10	10,40	165	1	3258951132142	
E113215B	20	240	42,70	30,20	7,20	10,90	180	1	3258951132159	
E113216B	21	250	45,50	31,70	7,50	11,40	195	1	3258951132166	
E113217B	22	260	48,70	33,80	8	11,90	242	1	3258951132173	
E113218B	23	260	48,70	33,80	8	11,90	235	1	3258951132180	
E113219B	24	280	50,70	35,80	8,20	12,90	280	1	3258951132197	
E113220B	25	295	52,70	38,70	8,70	13,40	325	1	3258951132203	
E113221B	26	295	52,70	38,70	8,70	13,40	325	1	3258951132210	
E113222B	27	310	56,20	40,20	8,90	14,40	370	1	3258951132227	
E113223B	28	340	60,20	44,60	9,70	15,90	495	1	3258951132234	
E113224B	29	340	60,20	44,60	9,70	15,90	495	1	3258951132241	
E113225B	30	340	60,20	44,60	9,70	15,90	485	1	3258951132258	
E113226B	32	360	64,70	47,30	10,60	16,90	600	1	3258951132265	
E110101B	34	380	68,70	49,30	11,50	17,20	639	1	3258951101018	
E110102B	36	410	73,60	53,40	13	18,20	809	1	3258951101025	
E110103B	38	430	76,60	56,50	14,50	19	965	1	3258951101032	
E110104B	41	460	83,50	61,50	15,50	20	1 261	1	3258951101049	