

Voltage Selector Insert to KE, CE, KG, CG

Voltage selector inserts for power entry modules, types KE, CE, KG, CG



To be used with drawer for KE, CE, KG, CG



Description

- Component: Drop-in type, Switching Unit
- 1 Function: Voltage selector insert (step switch)
- Up to four different switch positions
- Approved together with power entry module

Other versions on request

- Fuse drawer with other voltage values


References

Fits to type:


Weblinks

[pdf](#), [General Product Information](#), [Approvals](#), [RoHS](#), [CHINA-RoHS](#), [Mating Connectors](#), [e-Store](#), [SCHURTER-Stock-Check](#), [Distributor-Stock-Check](#), [Accessories](#)


Dimensions

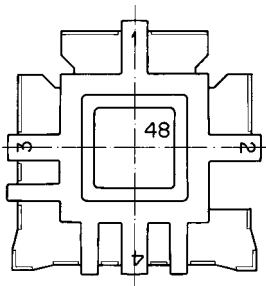

Switch position 1

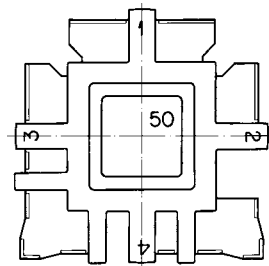


Switch position 2

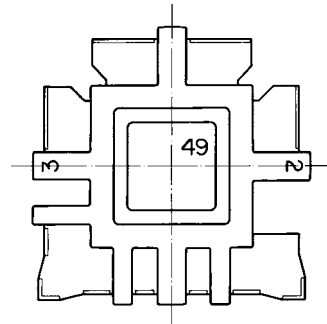


Diagrams

System No. 1

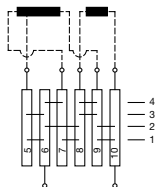


- 2 separate windings, one with a tap
- 3 or 4 switch positions
- 2 separate windings one with a tap
- 3 or 4 switch positions

System No. 2

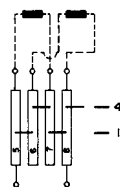


- 2 separate windings
- 2 switch positions
- 2 separate windings
- 2 switch positions

System No. 3

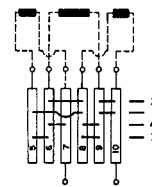

- 3 separate windings
- 3 or 4 switch positions
- 3 separate windings
- 3 or 4 switch positions

System No. 4

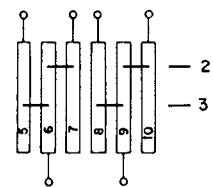

- 2-pole change over switch
- 2-pole change-over switch

Voltage Selector Inserts

| Switch position | System No. | Voltage marking, switch position | | | | Order Number |
|-----------------|------------|----------------------------------|-------|-------|-------|--------------|
| | | 1 | 2 | 3 | 4 | |
| 1 | - | - | - | - | - | 4305.0048.00 |
| 1 | 1 | 100 | 120 | 220 | 240 | 4305.0048.01 |
| 1 | 3 | 130 | 110 | 240 | 220 | 4305.0048.02 |
| 1 | 2 | 110 | - | - | 220 | 4305.0048.03 |
| 1 | 3 | - | 110 | 240 | 220 | 4305.0048.04 |
| 1 | 2 | 115 | - | - | 230 | 4305.0048.05 |
| 1 | 1 | 130 | 110 | 240 | 220 | 4305.0048.08 |
| 1 | 2 | 120 | - | - | 240 | 4305.0048.09 |
| 1 | 1 | 100 | 115 | - | 230 | 4305.0048.10 |
| 1 | 2 | 230 | - | - | 110 | 4305.0048.11 |
| 1 | 1 | 240 | 230 | 220 | 200 | 4305.0048.15 |
| 1 | 4 | - | 115 | 230 | - | 4305.0048.17 |
| 1 | 1 | - | 110 | 220 | - | 4305.0048.18 |
| 1 | 1 | 100 | 120 | 230 | 240 | 4305.0048.20 |
| 1 | 1 | 110 | 130 | 230 | 50 | 4305.0048.21 |
| 1 | 2 | 911 | - | - | 082 | 4305.0048.22 |
| 1 | - | 110 | 115 | 215 | 230 | 4305.0048.23 |
| 1 | - | 100 V | 115 V | 215 V | 230 V | 4305.0048.24 |
| 1 | 2 | 100 | - | - | 200 | 4305.0048.25 |
| 1 | - | - | 911 | - | 082 | 4305.0048.28 |
| 1 | - | 100 | 120 | 220 | 230 | 4305.0048.30 |
| 3 | - | - | - | - | - | 4305.0049.00 |
| 3 | 4 | - | 022 | 011 | - | 4305.0049.07 |
| 3 | 4 | - | 115 | 230 | - | 4305.0049.17 |
| 3 | 1 | - | - | - | - | 4305.0049.18 |
| 3 | 4 | - | 082 | 011 | - | 4305.0049.19 |
| 2 | - | - | - | - | - | 4305.0050.00 |
| 2 | 3 | 130 | 110 | 240 | 220 | 4305.0050.02 |
| 2 | 3 | - | 110 | 240 | 220 | 4305.0050.04 |
| 2 | 3 | 150 | 110 | - | 220 | 4305.0050.06 |
| 2 | 3 | - | - | - | - | 4305.0050.26 |
| 2 | - | 100 | 120 | 220 | - | 4305.0050.30 |

Packaging unit 50 Pcs