


Extender Card

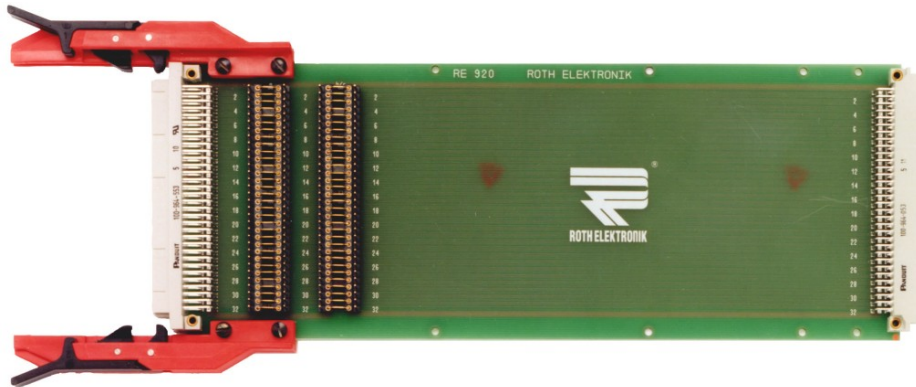

RE920C64/1LF



- extender card for 19"-systems DIN 41612 C64 a+c
- EPOXY fibre-glass FR4 1.50 mm single-sided 70 µm CU
- solder stop mask
- removable jumpers and two measuring posts for each track
- signalling line pin 2 - 31
- large signalling line pin 1 + 32
- switching voltage 10 mV - 60 V
- switching current 0.5 A bei 24 V
- rest current at 20° C, max. 2 A
- contact resistance 20 mOhm
- extender card: 100% electronically tested
- additional print at the component side