

Rose MX6 series



Ordering number FA10336
Description FA10336_MX6-RS

Family	Rose	FWHM	12 degrees
Type	Lens	Efficiency	89
LED	MX-6	cd/Im	-
Color	White	Gerber File	Available
Diameter	21.6 mm		
Height	13.5 mm		
Style	Square		
Optic Material	PC		
Holder Material	PC		
Fastening	-		
Status	Ready		



Ordering number FA10337
Description FA10337_MX6-SS

Family	Rose	FWHM	17 degrees
Type	Lens	Efficiency	88
LED	MX-6	cd/Im	-
Color	White	Gerber File	Available
Diameter	21.6 mm		
Height	13.5 mm		
Style	Square		
Optic Material	PC		
Holder Material	PC		
Fastening	-		
Status	Ready		



Ordering number FA10338
Description FA10338_MX6-D

Family	Rose	FWHM	17 degrees
Type	Lens	Efficiency	87
LED	MX-6	cd/Im	-
Color	White	Gerber File	Available
Diameter	21.6 mm		
Height	13.5 mm		
Style	Square		
Optic Material	PC		
Holder Material	PC		
Fastening	-		
Status	Ready		



Ordering number FA10339
Description FA10339_MX6-M

Family	Rose	FWHM	30 degrees
Type	Lens	Efficiency	86
LED	MX-6	cd/Im	-
Color	White	Gerber File	Available
Diameter	21.6 mm		
Height	13.5 mm		
Style	Square		
Optic Material	PC		
Holder Material	PC		
Fastening	-		
Status	Ready		

Rose MX6 series



Ordering number FA10340
Description FA10340_MX6-O

Family	Rose	FWHM	44+18 degrees
Type	Lens	Efficiency	83
LED	MX-6	cd/Im	-
Color	White	Gerber File	Available
Diameter	21.6 mm		
Height	13.5 mm		
Style	Square		
Optic Material	PC		
Holder Material	PC		
Fastening	-		
Status	Ready		




Ordering number FA10344
Description FA10344_MX6-W

Family	Rose	FWHM	degrees
Type	Lens	Efficiency	84
LED	MX-6	cd/Im	-
Color	White	Gerber File	Available
Diameter	21.6 mm		
Height	13.5 mm		
Style	Square		
Optic Material	PC		
Holder Material	PC		
Fastening	-		
Status	Ready		



Ordering number CA10608
Description CA10608_MX6-2-D

Family	Rose	FWHM	17 degrees
Type	Lens	Efficiency	-
LED	MX-6	cd/Im	-
Color	White	Gerber File	Available
Diameter	21.6 mm		
Height	13.5 mm		
Style	Square		
Optic Material	PMMA		
Holder Material	PC		
Fastening	-		
Status	Ready		

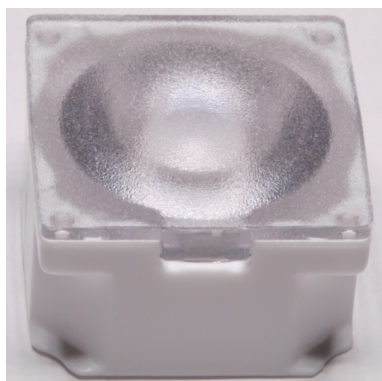

Ordering number FA10903
Description FA10903_MX6-W-V6

Family	Rose	FWHM	66 degrees
Type	Lens	Efficiency	84
LED	MX-6	cd/Im	-
Color	White	Gerber File	Available
Diameter	21.6 mm		
Height	13.5 mm		
Style	Square		
Optic Material	PC		
Holder Material	PC		
Fastening	-		
Status	Ready		

Rose MX6 series



Ordering number 4FA11151
Description 4FA11151_MX6-O-90

Family	Rose	FWHM	44+18 degrees
Type	Lens	Efficiency	-
LED	MX-6	cd/Im	-
Color	White	Gerber File	Available
Diameter	21.6 mm		
Height	13.5 mm		
Style	Square		
Optic Material	PC		
Holder Material	PC		
Fastening	-		
Status	Ready		