


# Desoldering Tips

for MFR-DSX, -DSI, -SDX and -SDI Systems

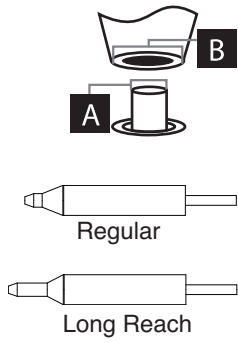

Part No.	Description	Ø A	Ø B
DFP-CN2	Desolder Tip	0.67mm (.026")	0.67mm (.026")
DFP-CN3	Desolder Tip	0.79mm (.031")	2.05mm (.080")
DFP-CN4	Desolder Tip	1.05mm (.041")	2.30mm (.090")
DFP-CN5	Desolder Tip	1.31mm (.052")	2.65mm (.104")
DFP-CN6	Desolder Tip	1.55mm (.061")	2.85mm (.112")
DFP-CN7	Desolder Tip	2.44mm (.096")	3.65mm (.143")
DFP-CNL3	Desolder Tip Long Reach	0.79mm (.031")	2.05mm (.080")
DFP-CNL4	Desolder Tip Long Reach	1.05mm (.041")	2.30mm (.090")
DFP-CNL5	Desolder Tip Long Reach	1.31mm (.052")	2.65mm (.104")

The second digit denotes substrate material (damage tolerance). **F**= FR4 / Glass Fiber, for most standard applications. Also available in C Series, **C** = Ceramic.

# Soldering Tips

for MFR-PST and PS-800E Systems with MFR-CA2 and PS-CA2 coils

**EASY ACCESS SOLDERING TIPS** for longer reach touch up applications

	<b>SFV-CN05A</b> Conical Solder Tip 0.5mm (.02")		<b>SFV-CH18A</b> Fine Solder Tip 1.8mm (.07")
	<b>SFV-CNL10A</b> Conical Long Solder Tip 1.0mm (.04")		<b>SFV-CH15A</b> Chisel Solder Tip 1.5mm (.06")
	<b>SFV-CH50A</b> Chisel Solder Tip 5.0mm (.197")		<b>SFV-CNL03A</b> Conical Long Solder Tip 0.3mm (.01")
	<b>SFV-CH25A</b> Chisel Solder Tip 2.5mm (.10")		<b>SFV-CNB04A</b> Conical Bent Solder Tip 0.4mm (.016")
	<b>SFV-CH10A</b> Chisel Solder Tip 1.0mm (.04")		<b>SFV-DRH430A</b> Drag Solder Tip Hoof, 3.0mm (.12")
	<b>SFV-DRH420A</b> Hoof Solder Tip 45° 2.0mm (.08")		<b>SFV-DRK45A</b> Knife Solder Tip 4.5mm (.177")
			<b>SFV-DRK30A</b> Knife Solder Tip 3.0mm (.12")

**SOLDERING TIPS** for heavy duty applications

	<b>SFV-CH10</b> Chisel Solder Tip 30° 1.0mm (.04")		<b>SFV-CNL10</b> Conical Long Solder Tip 1.0mm (.04")
	<b>SFV-CH20</b> Chisel Solder Tip 2.0mm (.08")		<b>SFV-CNL14</b> Conical Long Solder Tip 1.4mm (.056")
	<b>SFV-CH25</b> Chisel Solder Tip 2.5mm (.10")		<b>SFV-DRH20</b> Conical Bevel Solder Tip 2.0mm (.08")