


Teel

616-837 replaces 448-357

October 95

SPARKRITE

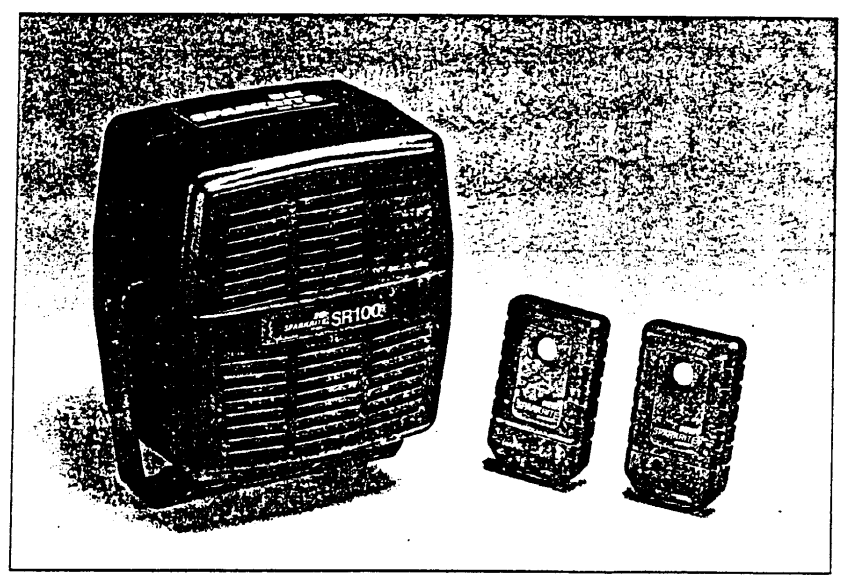

REMOTE CAR
ALARM SYSTEM

SR100 M/O

Technical Helpline - 04129-862616

Includes ultrasonic
unit 449-118.



SPARKRITE SR100

ADVANCED REMOTE CONTROL CAR ALARM SYSTEM

The Sparkrite SR100 compact radio control alarm system incorporates the latest "state-of-the-art" microprocessor technology offering the ultimate in product reliability and performance.

The unique easy-fit design ensures easy installation and guarantees many years of trouble free operation

SR100 FEATURES

- Two Radio remote control transmitters—DTI approved, Instant arm/disarm.
- Passive arming option—allows automatic arming on closure of last door. Disarming via remote control.
- Powerful built-in 128dB siren.
- Built-in electronic impact sensor—detects forced entry or shock to the vehicle.
- Remote control panic feature—provides personal protection sounding siren for up to 30 seconds.
- Starter motor circuit immobilisation—disables vehicle when alarm sounding.
- Arming and disarming confirmed by a "chirp" from the siren and flashing of the indicators.
- Siren sounds and indicators flash for 30 seconds (nominal) when the alarm is triggered.
- Flashing LED light for dashboard mounting.
- A highly visible deterrant.
- Current sensing — detects door opening when interior light switches on.
- Audible signal on disarming if attempted break in has occurred.
- Valet key switch over-ride feature.
- Electric cooling fan inhibit—prevents false triggering of current sense circuit.
- Security circuit prevents accidental arming.
- Automatic reset giving continuous protection until disarmed by remote control.
- Door locking control wire. Allows doors to be locked/unlocked by remote control when connected to SR911 Central Door Locking Interface.
- Sensor connection—quick-fit plug allows connection of a range of optional ultrasonic interior detectors.