


616-862, replaces 449-106.
OCTOBER 95

SPARKRITE

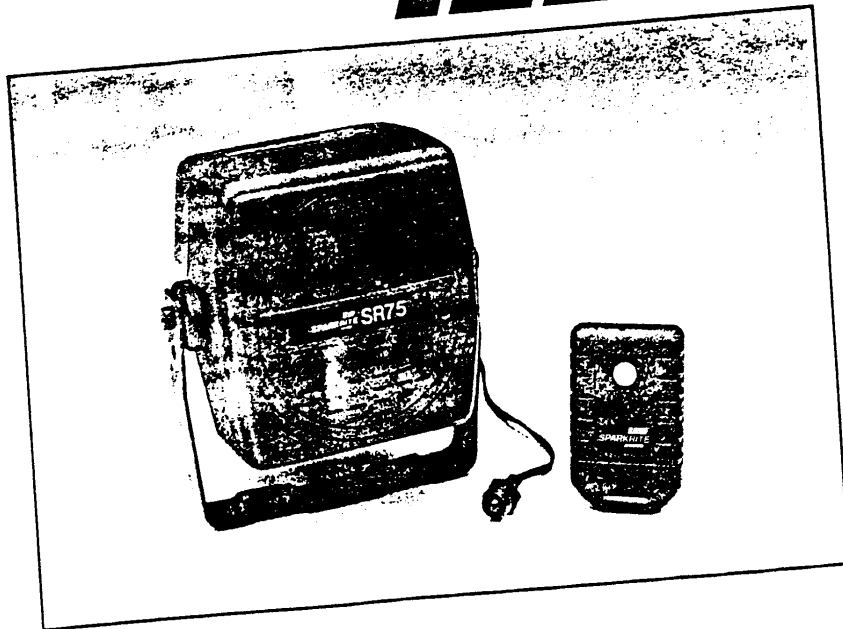

REMOTE CONTROL
CAR ALARM
SYSTEM

SR75

SR75 FEATURES

- ✓ ■ Radio remote control DTI approved. Instant arm/disarm.
- ✓ ■ Powerful integral 128Db siren.
- ✓ ■ Integral electronic shock sensor. Detects forced entry or shock due to exterior attack.
- ✓ ■ Remote control panic. Provides additional personal protection by sounding siren for up to 30 secs.
- ✓ ■ Arming and disarming confirmed by chirp from siren.
- ✓ ■ Siren sounds for 30 secs (nominal) when alarm is triggered.
- ✓ ■ Current sensing. Detects door opening when interior light is switched on.
- ✓ ■ Entry alert. Audible signal on disarming if attempted break in has occurred.
 - Electric fan inhibit. Prevents false alarms due to cooling fan running after alarm is armed.
- ✓ ■ Alarm armed LED (Light Emitting Diode) as a visible deterrent.
- ✓ ■ Automatic reset. Gives continuous protection until alarm is disarmed by remote control.
 - Door locking control wire. Allows doors to be locked/unlocked by remote control when connected to SR911 Central Door Locking Interface.
 - Sensor connection. Quick fit plug allows connection of interior detector units such as Sparkrite SR915 with separate professional style sensors, SR913 with scanning LED's or SR922 Hyper-Frequency Radar Detector.