



 



# Terminal Block Accessories

## Kliptite (Quick Connect) - Single Row

### Specifications:

Kliptite (Quick Connect) accept standard female wire terminals. These Klipties are ideal for applications that require a positive, yet quick disconnect termination. Kliptites are assembled to the block with screws or, in some applications, riveted to the block.


Kliptites are available in 0°, 45° or 90° bends; one side or two side. Material: Brass; Finish: Tin

Screw Construction	Rivet Construction	Tab Width	Tab Thickness	(2) 0° tabs	(2) 45° tabs	(2) 90° tabs	(1) 0° tab	(1) 45° tab	(1) 90° tab
									
411 Series		0.110	0.020	KT10	KT11	KT12	KT16	KT17	KT18
599 Series	799 Series	0.187	0.020	KT28	KT29	KT30	KT34	KT35	KT36
699 Series	899 Series	0.250	0.032	KT46	KT47	KT48	KT52	KT53	KT54
812 Series	912 Series	0.250	0.032	KT73	KT74	KT75	KT79	KT80	KT81
1690 Series <sup>1</sup>		0.250	0.032	KT46	KT47	KT48	KT52	KT53	KT54
2590 Series <sup>2</sup>		0.187	0.020	KT28	KT29	KT30	KT34	KT35	KT36
2690 Series <sup>3</sup>		0.250	0.032	KT46	KT47	KT48	KT52	KT53	KT54

- 1) 1690 Series insulated feed-thru blocks use the 699 Series Kliptites
- 2) 2590 Series use the 599 Series Kliptites
- 3) 2690 Series PC block use the 699 Kliptites

 


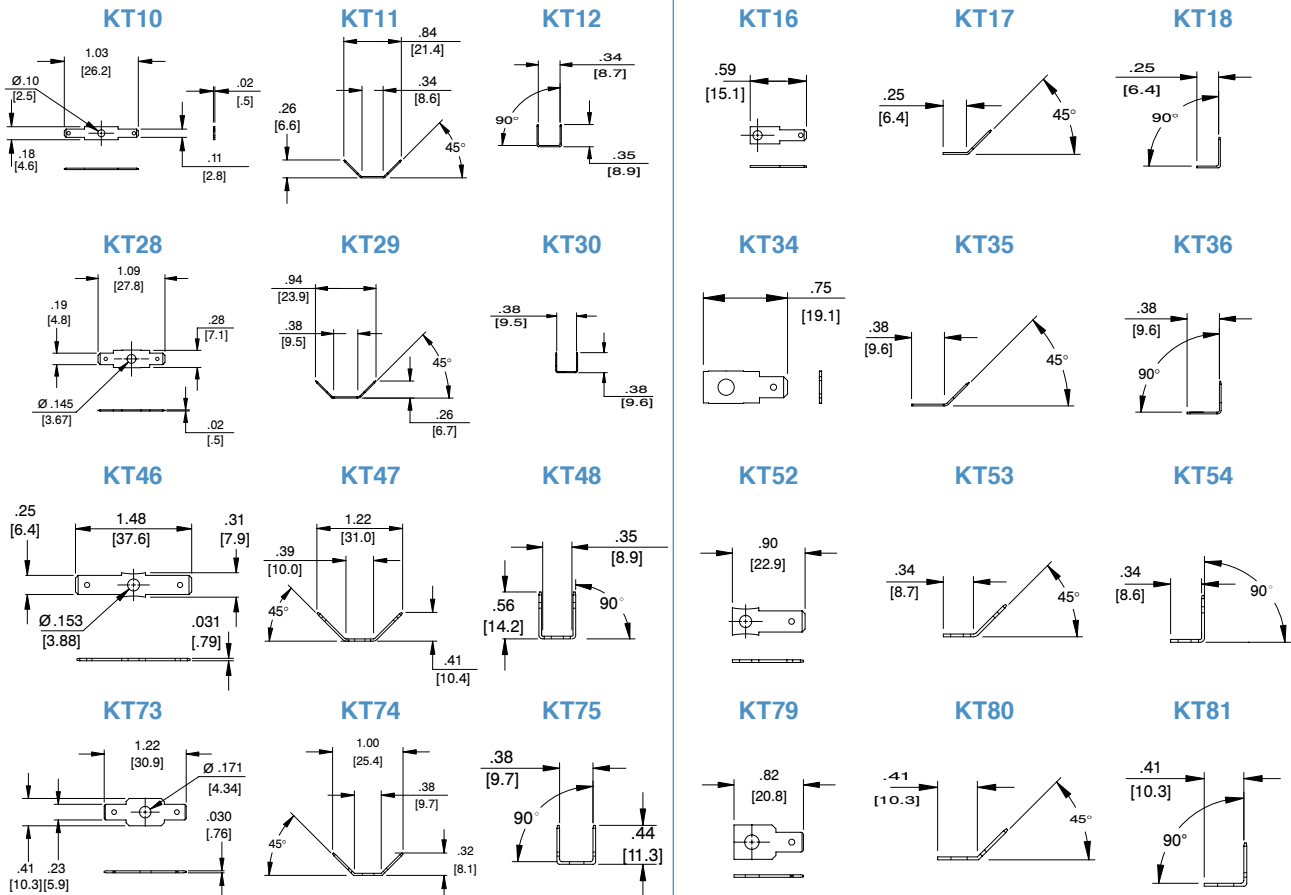


### TWO SIDE TABS

### ONE SIDE TABS



# Terminal Block Accessories


## Kliptite (Quick Connect) - Double Row

Screw Construction	Rivet Construction	Tab Width	Tab Thickness	(2) 0° tabs	(2) 45° tabs	(2) 90° tabs	(1) 0° tab	(1) 45° tab	(1) 90° tab
									
100 Series <sup>4</sup>		0.187	0.020	KT19	KT20	KT21	KT25	KT26	KT27
200 Series <sup>5</sup>		0.250	0.032	KT37	KT38	KT39	KT43	KT44	KT45
300 Series <sup>6</sup>		0.250	0.032	KT55	KT56	KT57	KT61	KT62	KT63
400 Series		0.250	0.032	KT67	KT68	KT69	KT64	KT65	KT66
600 Series		0.187	0.020	KT19	KT20	KT21	KT25	KT26	KT27
600A Series		0.187	0.020	KT19	KT20	KT21	KT25	KT26	KT27
601 Series	800A Series	0.250	0.032	KT37	KT38	KT39	KT43	KT44	KT45
602 Series	801 Series	0.250	0.032	KT55	KT56	KT57	KT61	KT62	KT63
603 Series	802 Series	0.250	0.032	KT67	KT68	KT69	KT64	KT65	KT66
621 RZ Series <sup>5</sup>		0.250	0.032	KT37	KT38	KT39	KT43	KT44	KT45
670A GP Series <sup>4</sup>		0.187	0.020	KT19	KT20	KT21	KT25	KT26	KT27
670A RZ Series <sup>4</sup>		0.187	0.020	KT19	KT20	KT21	KT25	KT26	KT27
671 GP Series <sup>5</sup>		0.250	0.032	KT37	KT38	KT39	KT43	KT44	KT45
671 RZ Series <sup>5</sup>		0.250	0.032	KT37	KT38	KT39	KT43	KT44	KT45
672 GP Series <sup>6</sup>		0.250	0.032	KT55	KT56	KT57	KT61	KT62	KT63
672 RZ Series <sup>6</sup>		0.250	0.032	KT55	KT56	KT57	KT61	KT62	KT63

- 4) 100, 670A GP, 670A RZ Series use the 600, 600A Series Kliptites  
 5) 200, 671 GP, 671 RZ, 621 RZ Series use the 601 Series Kliptites  
 6) 300, 672 GP, 672 RZ Series use the 602 Series Kliptites

- MSP Catalog Designations:  
 2-SIDE TABS: F1 (0°), F2 (45°), F3 (90°)  
 1-SIDE TABS: HF1 (0°), HF2 (45°), HF3 (90°)

### TWO SIDE TABS

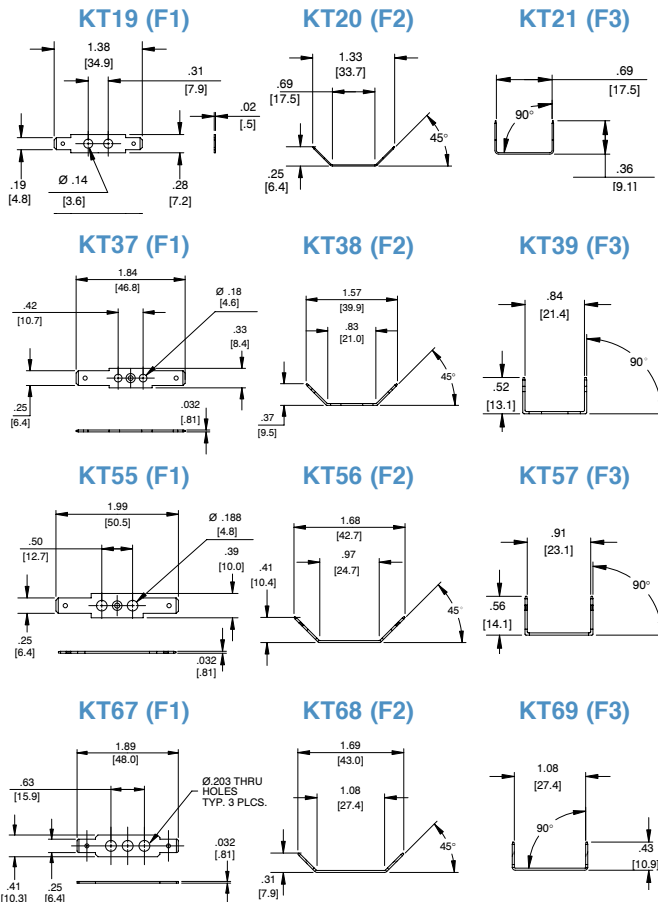

### ONE SIDE TABS

