




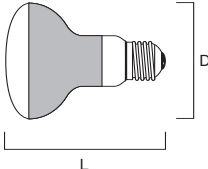


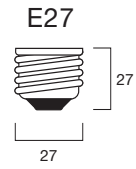

Reflector Coloured

<table border="1"> <tr> <td></td> <td>R63</td> <td>R80</td> </tr> <tr> <td>L</td> <td>103</td> <td>110</td> </tr> <tr> <td>D</td> <td>63</td> <td>80</td> </tr> </table>  		R63	R80	L	103	110	D	63	80	
	R63	R80								
L	103	110								
D	63	80								
<ul style="list-style-type: none"> 1 Blown glass reflector lamps 1 Coloured crown and integral aluminium reflector 1 Choice of 4 colours – Blue, Green, Red and Yellow 1 Available in 2 diameters: 63 and 80mm 1 To create special lighting effects in bars, clubs and discos as well as shop windows 										

Code	Description	Watt	Volt	Cap	Crown Finish	Packing Qty
Reflector Coloured R63 63mmØ						
0015660	40W 240V R63 Blue	40W	240V	E27	Blue	100
0015661	40W 240V R63 Red	40W	240V	E27	Red	100
0015662	40W 240V R63 Green	40W	240V	E27	Green	100
0015663	40W 240V R63 Yellow	40W	240V	E27	Yellow	100
Reflector Coloured R80 80mmØ						
0015700	60W 240V R80 Blue	60W	240V	E27	Blue	100
0015701	60W 240V R80 Red	60W	240V	E27	Red	100
0015702	60W 240V R80 Green	60W	240V	E27	Green	100
0015703	60W 240V R80 Yellow	60W	240V	E27	Yellow	100

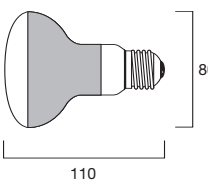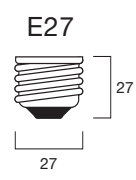Reflector Neodymium

 	
<ul style="list-style-type: none"> 1 Special neodymium glass which filters out yellow rays for a natural daylight effect 1 Improved light quality enhancing colours 1 E27 cap 1 Particularly suitable for craft and hobby work 1 In shops selling fabrics, jewels, food etc 	

Code	Description	Watt	Volt	Luminous Intensity	Beam Angle	Cap	Crown Finish	Packing Qty
Reflector Neodymium R80								
0015587	100W 240V E27 50° Pearl	100W	240V	780 cd	50°	E27	Pearl	100