

335 **0%**
MERCURY

SR512SW
Watch Battery OEM

Technical Data Sheet


Specifications

Chemical system	Zinc / Monovalent Silver Oxide, low drain
Nominal Voltage	1,55 V
Capacity	6 mAh, Discharge over 82,5 kΩ at 23±3°C to 1,2 V
Operating Temperature	0°C – 60°C
Self Discharge	Less than 7% per year at 23±3°C
Nominal Weight	~0,13 g

Dimensions


(according IEC 60086-3)

Diameter	5,80 mm (0,228")
Height	1,25 mm (0,049")

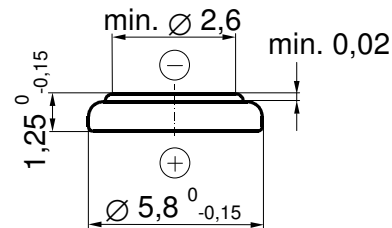

Discharge Curve

Constant Load	82,5 kΩ
Starting Drain	18,9 μA
Temperature	23±3°C

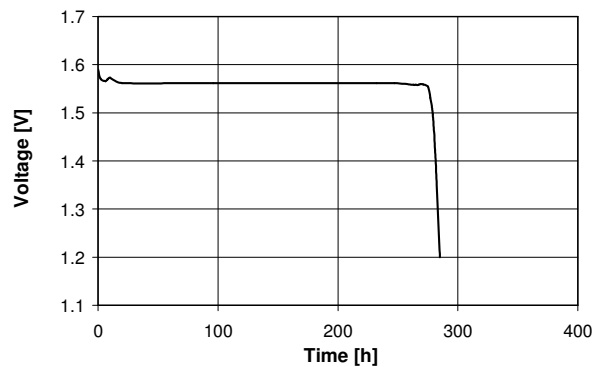

Information and contents in this data sheet are for reference purpose only. They do not constitute any warranty or representation and are subject to change without notice. For most current information and further details, please contact your Renata representative. For safety related information please consult the PSDS document related to that product or product family.

Rev. 335MF_OEM.04 2011/05