



Patchcord, Fibre, Duplex, ST-ST, OS1

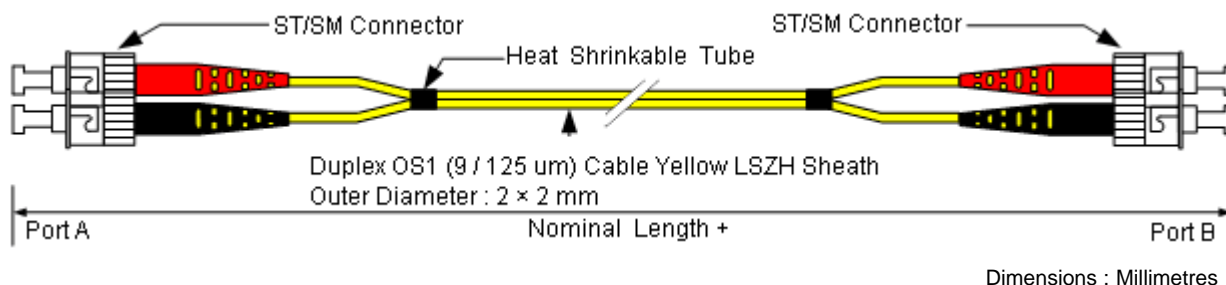

Specifications

		Port A	Port B
Connector Type		ST/SM	ST/SM
Connector Body	Material	Zn Alloy	Zn Alloy
	Colour	-	-
Connector Boot	Material	Plastic	Plastic
	Colour	Red and Black	Red and Black
Patchcord Length (Metre)		Customized	
Optical Cable	Fibre Type	OS1 9 / 125 um	
	Fibre Count	2	
	Outer Sheath	LSZH	
	Cable Outer Diameter	2 x 2 mm	
	Strength Member	DuPont Kevlar	
	Outer Sheath	LSZH	
	Cable Colour	Yellow	
Ferrule	Diameter	2.5 mm	2.5 mm
	Type	SM/PC	SM/PC
	Material	ZrO2 (Ceramic)	ZrO2 (Ceramic)
Connection at Cable		Crimp	Crimp
Connection at Fibre		353ND Glue	353ND Glue
Connection at Adapter		Twist - Lock Bayonet	Twist - Lock Bayonet
Polishing		UPC	UPC
Insertion Loss (dB)		< 0.3	< 0.3
Return Loss (dB)		> 50	> 50

Patchcord, Fibre, Duplex, SC-ST, OS1

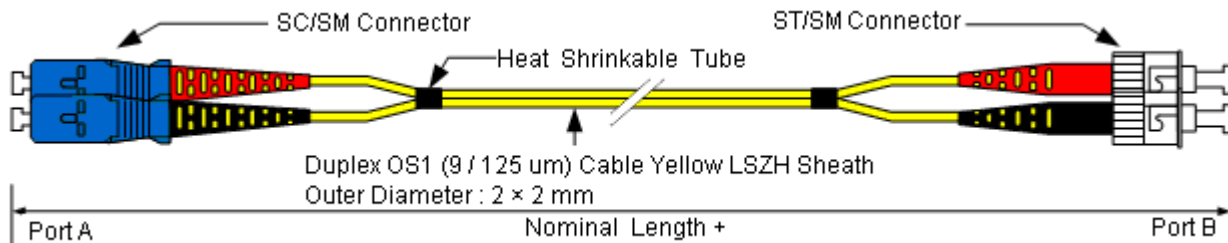


Dimensions : Millimetres

Specifications

		Port A	Port B
Connector Type		SC/SM	ST/SM
Connector Body	Material	Plastic	Zn Alloy
	Colour	Blue	-
Connector Boot	Material	Plastic	Plastic
	Colour	Red and Black	Red and Black
Patchcord Length (Metre)		Customized	
Optical Cable	Fibre Type	OS1 9 / 125 um	
	Fibre Count	2	
	Outer Sheath	LSZH	
	Cable Outer Diameter	2 x 2 mm	
	Strength Member	DuPont Kevlar	
	Outer Sheath	LSZH	
	Cable Colour	Yellow	
Ferrule	Diameter	2.5 mm	2.5 mm
	Type	SM/PC	SM/PC
	Material	ZrO2 (Ceramic)	ZrO2 (Ceramic)
Connection at Cable		Crimp	Crimp
Connection at Fibre		353ND Glue	353ND Glue
Connection at Adapter		Plug - In	Twist - Lock Bayonet
Polishing		UPC	UPC
Insertion Loss (dB)		< 0.3	< 0.3
Return Loss (dB)		> 50	> 50


Patchcord, Fibre, Duplex, SC-SC, OS1

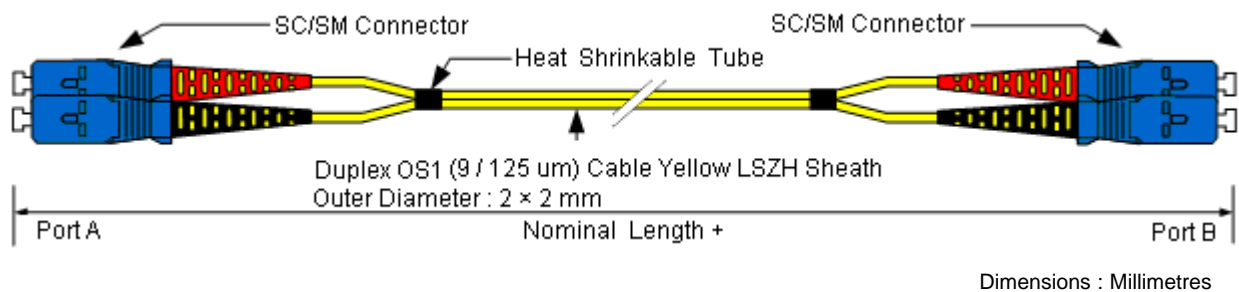

Specifications

		Port A	Port B
Connector Type		SC/SM	SC/SM
Connector Body	Material	Plastic	Plastic
	Colour	Blue	Blue
Connector Boot	Material	Plastic	Plastic
	Colour	Red and Black	Red and Black
Patchcord Length (Metre)		Customized	
Optical Cable	Fibre Type	OS1 9 / 125 um	
	Fibre Count	2	
	Outer Sheath	LSZH	
	Cable Outer Diameter	2 x 2 mm	
	Strength Member	DuPont Kevlar	
	Outer Sheath	LSZH	
	Cable Colour	Yellow	
Ferrule	Diameter	2.5 mm	2.5 mm
	Type	SM/PC	SM/PC
	Material	ZrO2 (Ceramic)	ZrO2 (Ceramic)
Connection at Cable		Crimp	Crimp
Connection at Fibre		353ND Glue	353ND Glue
Connection at Adapter		Plug - In	Plug - In
Polishing		UPC	UPC
Insertion Loss (dB)		< 0.3	< 0.3
Return Loss (dB)		> 50	> 50


Patchcord, Fibre, Duplex, LC-LC, OS1

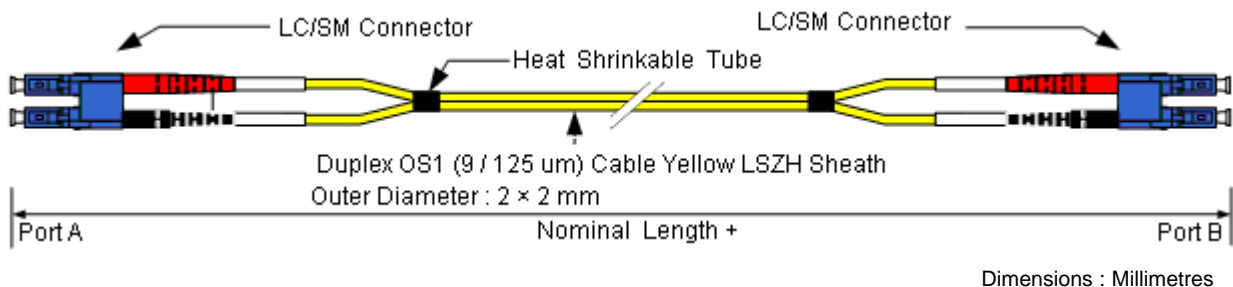

Specifications

		Port A	Port B
Connector Type		LC/SM	LC/SM
Connector Body	Material	Plastic	Plastic
	Colour	Blue	Blue
Connector Boot	Material	Plastic	Plastic
	Colour	Red and Black	Red and Black
Patchcord Length (Metre)		Customized	
Optical Cable	Fibre Type	OS1 9 / 125 um	
	Fibre Count	2	
	Outer Sheath	LSZH	
	Cable Outer Diameter	2 x 2 mm	
	Strength Member	DuPont Kevlar	
	Outer Sheath	LSZH	
	Cable Colour	Yellow	
Ferrule	Diameter	1.25 mm	1.25 mm
	Type	SM/PC	SM/PC
	Material	ZrO2 (Ceramic)	ZrO2 (Ceramic)
Connection at Cable		Crimp and Heat Shrinkable Tubing	Crimp and Heat Shrinkable Tubing
Connection at Fibre		353ND Glue	353ND Glue
Connection at Adapter		RJ45 Style	RJ45 Style
Polishing		UPC	UPC
Insertion Loss (dB)		< 0.3	< 0.3
Return Loss (dB)		> 50	> 50

Patchcord, Fibre, Duplex, LC-SC, OS1

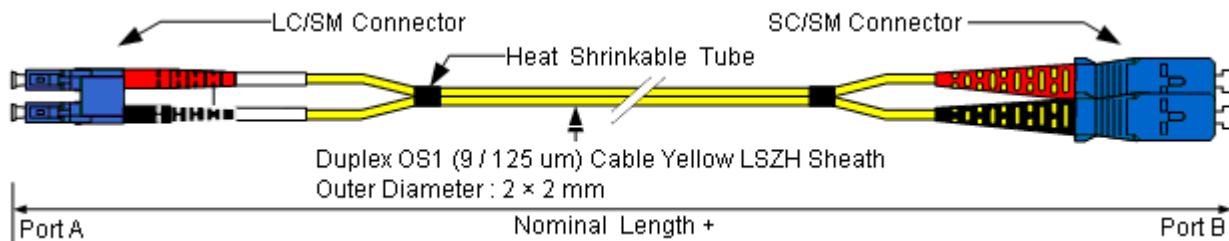


Dimensions : Millimetres

Specifications

		Port A	Port B
Connector Type		LC/SM	SC/SM
Connector Body	Material	Plastic	Plastic
	Colour	Blue	Blue
Connector Boot	Material	Plastic	Plastic
	Colour	Red and Black	Red and Black
Patchcord Length (Metre)		Customized	
Optical Cable	Fibre Type	OS1 9 / 125 um	
	Fibre Count	2	
	Outer Sheath	LSZH	
	Cable Outer Diameter	2 x 2 mm	
	Strength Member	DuPont Kevlar	
	Outer Sheath	LSZH	
	Cable Colour	Yellow	
Ferrule	Diameter	1.25 mm	2.5 mm
	Type	SM/PC	SM/PC
	Material	ZrO2 (Ceramic)	ZrO2 (Ceramic)
Connection at Cable		Crimp and Heat Shrinkable Tubing	Crimp
Connection at Fibre		353ND Glue	353ND Glue
Connection at Adapter		RJ45 Style	Plug - In
Polishing		UPC	UPC
Insertion Loss (dB)		< 0.3	< 0.3
Return Loss (dB)		> 50	> 50

Patchcord, Fibre, Duplex, LC-ST, OS1

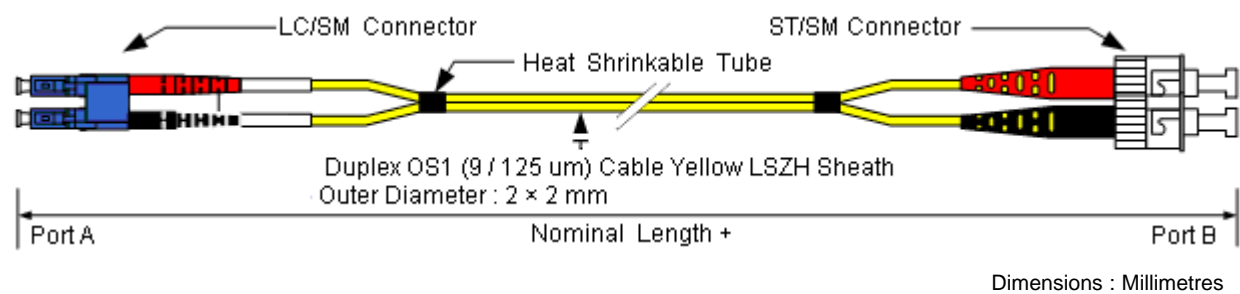

Specifications

		Port A	Port B
Connector Type		LC/SM	ST/SM
Connector Body	Material	Plastic	Zn Alloy
	Colour	Blue	-
Connector Boot	Material	Plastic	Plastic
	Colour	Red and Black	Red and Black
Patchcord Length (Metre)		Customized	
Optical Cable	Fibre Type	OS1 9 / 125 um	
	Fibre Count	2	
	Outer Sheath	LSZH	
	Cable Outer Diameter	2 × 2 mm	
	Strength Member	DuPont Kevlar	
	Outer Sheath	LSZH	
	Cable Colour	Yellow	
Ferrule	Diameter	1.25 mm	2.5 mm
	Type	SM/PC	SM/PC
	Material	ZrO2 (Ceramic)	ZrO2 (Ceramic)
Connection at Cable		Crimp and Heat Shrinkable Tubing	Crimp
Connection at Fibre		353ND Glue	353ND Glue
Connection at Adapter		RJ45 Style	Twist - Lock Bayonet
Polishing		UPC	UPC
Insertion Loss (dB)		< 0.3	< 0.3
Return Loss (dB)		> 50	> 50

Part Number Table

Description	Part Number
Patchcord, Fibre, Duplex, ST-ST, OS1, 1M	PS11336
Patchcord, Fibre, Duplex, ST-ST, OS1, 2M	PS11337
Patchcord, Fibre, Duplex, ST-ST, OS1, 3M	PS11338
Patchcord, Fibre, Duplex, ST-ST, OS1, 5M	PS11339
Patchcord, Fibre, Duplex, ST-ST OS1, 10M	PS11340
Patchcord, Fibre, Duplex, SC-ST, OS1, 1M	PS11341
Patchcord, Fibre, Duplex, SC-ST, OS1, 2M	PS11342
Patchcord, Fibre, Duplex, SC-ST, OS1, 3M	PS11343
Patchcord, Fibre, Duplex, SC-ST, OS1, 5M	PS11344
Patchcord, Fibre, Duplex, SC-ST, OS1, 10M	PS11345
Patchcord, Fibre, Duplex, SC-SC, OS1, 1M	PS11346
Patchcord, Fibre, Duplex, SC-SC, OS1, 2M	PS11347
Patchcord, Fibre, Duplex, SC-SC, OS1, 3M	PS11348
Patchcord, Fibre, Duplex, SC-SC, OS1, 5M	PS11349
Patchcord, Fibre, Duplex, SC-SC OS1, 10M	PS11350
Patchcord, Fibre, Duplex, LC-LC, OS1, 1M	PS11351
Patchcord, Fibre, Duplex, LC-LC, OS1, 2M	PS11352
Patchcord, Fibre, Duplex, LC-LC, OS1, 3M	PS11353
Patchcord, Fibre, Duplex, LC-LC, OS1, 5M	PS11354
Patchcord, Fibre, Duplex, LC-LC OS1, 10M	PS11355
Patchcord, Fibre, Duplex, LC-SC, OS1, 1M	PS11356
Patchcord, Fibre, Duplex, LC-SC, OS1, 2M	PS11357
Patchcord, Fibre, Duplex, LC-SC, OS1, 3M	PS11358
Patchcord, Fibre, Duplex, LC-SC, OS1, 5M	PS11359
Patchcord, Fibre, Duplex, LC-SC OS1, 10M	PS11360
Patchcord, Fibre, Duplex, LC-ST, OS1, 1M	PS11361
Patchcord, Fibre, Duplex, LC-ST, OS1, 2M	PS11362
Patchcord, Fibre, Duplex, LC-ST, OS1, 3M	PS11363
Patchcord, Fibre, Duplex, LC-ST, OS1, 5M	PS11364
Patchcord, Fibre, Duplex, LC-ST OS1, 10M	PS11365

Important Notice : This data sheet and its contents (the "Information") belong to the members of the Premier Farnell group of companies (the "Group") or are licensed to it. No licence is granted for the use of it other than for information purposes in connection with the products to which it relates. No licence of any intellectual property rights is granted. The Information is subject to change without notice and replaces all data sheets previously supplied. The Information supplied is believed to be accurate but the Group assumes no responsibility for its accuracy or completeness, any error in or omission from it or for any use made of it. Users of this data sheet should check for themselves the Information and the suitability of the products for their purpose and not make any assumptions based on information included or omitted. Liability for loss or damage resulting from any reliance on the Information or use of it (including liability resulting from negligence or where the Group was aware of the possibility of such loss or damage arising) is excluded. This will not operate to limit or restrict the Group's liability for death or personal injury resulting from its negligence. pro-SIGNAL is the registered trademark of the Group. © Premier Farnell plc 2011.