




## Product information EF124 PVC4x034L0200 50

Industrial Connectors:Archive - Industrial Connectors:Circular Connectors E-series M12 / M12 push-pull (Archive):with screw locking:Straight cable socket with integrally molded lead:EF124

PVC4x034L0200 50

<http://www.e-catalog.beldensolutions.com/link/57078-24228-62529-24256-24257-24258-34369/en/conf/uistate>

<b>Name</b>	EF124 PVC4x034L0200 50
	
	Straight cable socket, with integrally molded lead, self-securing screw locking
<b>Delivery informations</b>	
<b>Availability</b>	no longer available
<b>Product description</b>	
<b>Description</b>	Straight cable socket, with integrally molded lead, self-securing screw locking
<b>Type</b>	EF124 PVC4x034L0200 50
<b>Order No.</b>	934 401-101
<b>Other standard types</b>	black housing, cable material PVC, cable length 5 m: order no. 934 401-100; black housing, cable material PUR, cable length 2 m: order no. 934 401-201; cable length 5 m: order no. 934 401-200
<b>Type of contact</b>	female
<b>Number of contacts</b>	4
<b>Cable material</b>	PVC
<b>Cable color</b>	black
<b>Cable length</b>	2 m
<b>Conductor size</b>	0.34 mm <sup>2</sup>
<b>Cable specification</b>	high flexible lead
<b>Cable type</b>	LiYY
<b>Standard</b>	IEC 61076-2-101 (Ed. 1)/ IEC 60947-5-2
<b>Housing Color</b>	black
<b>Technical data</b>	
<b>Wire stranding</b>	42 x 0.1
<b>Rated voltage</b>	AC/DC 250 V
<b>Rated current</b>	4 A
<b>Material</b>	
<b>Contact material</b>	Cu Sn 6
<b>Contact surface material</b>	Au
<b>Contact bearer material</b>	PUR
<b>Housing material</b>	PUR
<b>Coupling nut material</b>	Zn Al/Ni
<b>O-Ring</b>	Viton
<b>Environmental conditions</b>	
<b>Protection class (IEC 60529)</b>	IP 68
<b>Pollution severity</b>	3
<b>Temperature range</b>	-25°C to +90°C (connector)/+70°C (cable)
<b>Inflammability class</b>	
<b>Cable</b>	fire resist. IEC 60332-1
<b>Contact bearer</b>	complies with 94 HB
<b>Approvals</b>	
<b>UL</b>	UL-version on request
<b>Packing unit</b>	
<b>Packaging unit</b>	50 pieces
<b>Scope of delivery and accessories</b>	
<b>Accessories to order separately</b>	protective cap M 12 VS, order no. 734 209-100



# HIRSCHMANN

A BELDEN BRAND


Industrial Connectors:Archive - Industrial Connectors:Circular Connectors E-series M12 / M12 push-pull (Archive)-with screw locking:Straight cable socket with integrally molded lead:EF124

PVC4x034L0200 50

<http://www.e-catalog.beldensolutions.com/link/57078-24228-62529-24256-24257-24258-34369/en/conf/uistate>

## Picture

### Drawing

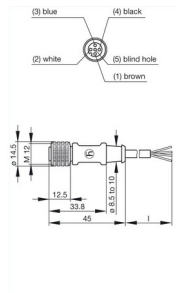

### Belden Deutschland GmbH

Im Gewerbepark 2

58579 Schalksmühle

Germany

Phone: +49 7127/14-1806

E-Mail: [icos-sales@belden.com](mailto:icos-sales@belden.com)

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.