




Product information EWM125 PUR5x034L0200 50

Industrial Connectors:Archive - Industrial Connectors:Circular Connectors E-series M12 / M12 push-pull (Archive):with screw locking:Angled cable plug with integrally molded lead:EWM125

PUR5x034L0200 50

<http://www.e-catalog.beldensolutions.com/link/57078-24228-62529-24256-24257-24266-34303/en/conf/ui/state>

Name	EWM125 PUR5x034L0200 50
	
	Angled cable plug, with integrally moulded lead, self-securing screw locking
Delivery informations	
Availability	no longer available
Product description	
Description	Angled cable plug, with integrally moulded lead, self-securing screw locking
Type	EWM125 PUR5x034L0200 50
Order No.	934 404-220
Other standard types	grip colour black, cable material PUR,cable length 5 m: order no. 934 404-221;grip colour black, cable material PVC,cable length 2 m: order no. 934 404-120;cable length 5 m: order no. 934 404-121
Type of contact	pin
Number of contacts	5
Cable material	PUR
Cable color	black
Cable length	2 m
Conductor size	0.34 mm ²
Cable specification	high flexible lead
Cable type	Li9YH-11YH
Standard	IEC 61076-2-101 (Ed.1)
Housing Color	black
Technical data	
Pin dimensions	1 mm
Wire stranding	42 x 0.1
Rated voltage	AC/DC 60 V
Rated current	4 A
Material	
Contact material	Cu Sn 6
Contact surface material	Au
Contact bearer material	PUR
Housing material	PUR
Coupling nut material	Zn Al/Ni
Environmental conditions	
Protection class (IEC 60529)	IP 68 / IP 69K
Pollution severity	3
Temperature range	-25 °C to +90 °C (UL: +80 °C)
Inflammability class	
Cable	fire resist. IEC 332-2
Contact bearer	94 HB
Approvals	
UL	UL
Packing unit	
Packaging unit	50 pieces


Industrial Connectors:Archive - Industrial Connectors:Circular Connectors E-series M12 / M12 push-pull (Archive)-with screw locking:Angled cable plug with integrally molded lead:EWM125

PUR5x034L0200 50

<http://www.e-catalog.beldensolutions.com/link/57078-24228-62529-24256-24257-24266-34303/en/conf/uistate>

Picture

Drawing

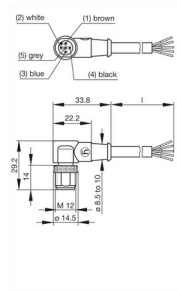

Belden Deutschland GmbH

Im Gewerbepark 2
58579 Schalksmühle
Germany
Phone: +49 7127/14-1806
E-Mail: icos-sales@belden.com

The information published in the websites has been compiled as carefully as possible. It is subject to alteration without notice in technical as well as in price-related/commercial respect. The complete information and data were available on user documentation. Mandatory information can only be obtained by a concrete query.