

Sta-Kon®



T&B Catalog Number:

F2035

UPC Number:


78621033515

Description:

Insulated Nylon Ferrule for Wire Size 14, Wire Size 2.5 mm², Length 0.591 inches, Blue

Status:

Active

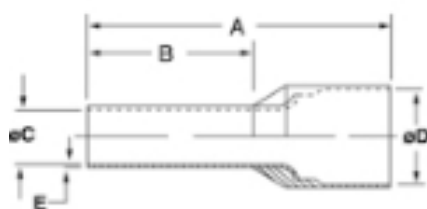

WEB_USE

-T&B Product Line	029
-US Cutsheet PDF Catalog Link	http://www-public.tnb.com/contractor/docs/stakon.pdf

Features

-	Ferrules ensure reliable electrical connections when terminating conductors in screw clamp terminal blocks.
---	---

General

-Ferrule Type	Insulated
-Insulation Type	Insulated Nylon
-Material	Copper
-Finish	Electro -Tin Plated
-Color	Blue
-Wire Range	14
-Wire Size (mm ²)	2.50

Dimension Information

-A (mm)	15.0
-B (mm)	8.0
-Diameter C (inches)	.091
-Diameter C (mm)	2.3
-Diameter D (inches)	.165
-Diameter D (mm)	4.2
-E (mm)	.15
-A (inches)	.591
-B (inches)	.315
-E (inches)	.006

Specifications

-Temperature Rating	105°C
-Voltage Rating	300V
-Flammability Rating	UL 94 V-2

Tooling

-Application Tools	T1, T3, ERG2
-Recommended Tool	T1, T3, ERG4

Packaging

-T&B Order Multiple	500
-T&B Inner Pack	500
-Package in Units	10000
-T&B Sold in UOM	Each
-T&B Weight Per UOM	0.04 lbs. per 100

Application Support

-Overview	Available on Website
-Wire Guide Tables	Available on Website

Notes

- Ferrule dimensions conform to DIN 46228, Part 4.

Certifications

-RoHS Compliance Yes

For further technical assistance, please contact us...

Thomas & Betts - USA
8155 T&B Blvd.
Memphis, TN 38125
www.tnb.com

T&B Technical Support
MS 3B-50
8155 T&B Blvd.
Memphis, TN 38125

Hours: 7AM - 6PM CDT
Monday-Friday
Phone: (888) 862-3289
Fax: (901) 252-1321
Email: techsupport@tnb.com