


# Sta-Kon®



**T&B Catalog Number:** RB14-250A  
**UPC Number:** 78621085676  
**Description:** Insulated Nylon Female - 250 Series Disconnects For Wire Range 16-14 Length 0.8, Tab Size .250 x .032 , Blue  
**Status:** Active

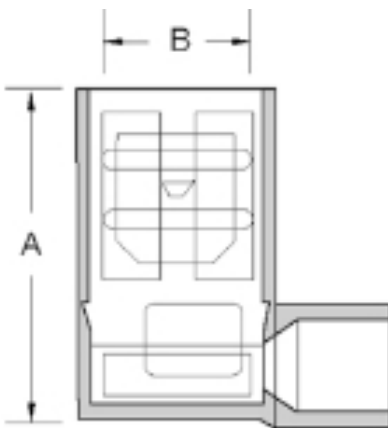

WEB_USE	
-T&B Product Line	029
-US Cutsheet PDF Catalog Link	<a href="http://www-public.tnb.com/contractor/docs/stakon.pdf">http://www-public.tnb.com/contractor/docs/stakon.pdf</a>

Features	
-	Unique construction of the female disconnect offers long-term dependability. Brazed seam serrated barrel provides maximum tensile strength.

General	
-Disconnect Type	Female - 250 Series
-Insulation Type	Insulated Nylon
-Terminal Series	RB
-Material	Brass
-Finish	Electro -Tin Plated
-Color	Blue
-Wire Range	16-14
-Tab Size	.250 x .032

Dimension Information	
-Maximum Insulation (inches)	.190
-A (inches)	.80
-B (inches)	.72

Specifications	
-Temperature Rating	105°C
-Voltage Rating	600V
-Flammability Rating	UL 94 V-2

Tooling	
-Tool Charts	Available on Website
-Application Tools	WT145C, WT2000, WT112M, ERG4001, ERG4003
-Recommended Tool	ERG4001

Packaging	
-T&B Order Multiple	50
-T&B Inner Pack	50
-Package in Units	250
-Package Type	Standard
-T&B Sold in UOM	Each
-T&B Weight Per UOM	0.56 lbs. per 100
-Alternate Package Qty	RB2577F

Application Support	
-Overview	Available on Website
-Wire Guide Tables	Available on Website

Certifications	
-RoHS Compliance	Yes

### Certifications



File Nbr:  
E66716

**For further technical assistance, please contact us...**

Thomas & Betts - USA  
8155 T&B Blvd.  
Memphis, TN 38125  
[www.tnb.com](http://www.tnb.com)

T&B Technical Support  
MS 3B-50  
8155 T&B Blvd.  
Memphis, TN 38125

Hours: 7AM - 6PM CDT  
Monday-Friday  
Phone: (888) 862-3289  
Fax: (901) 252-1321  
Email: [techsupport@tnb.com](mailto:techsupport@tnb.com)